


Test Adaptor for VMEbus

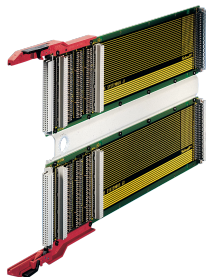

Test Adapter for VMEbus Boards to access test points on the board.

CERTIFICERINGER



FUNKTIONER

Routing and layer stack-up match the requirements of the VME bus

Measuring field for current and voltage measurement (V/I), (a)

Additional measuring pins, e.g. for the probe tips of an oscilloscope (b)

1 pin position for second test object, 1 pin position for terminator board

6 U test adaptors consist of two 3 U test adaptors linked via an intermediate adaptor

Voltage supply lines are designed for 2 A

SPECIFIKATIONER

Table 1/2

Katalognummer	Type	Connector Type	Board Depth	Rack Height	Measuring Field	Number of Layers
23022-002	VMEbus	C96, System Bus, C96, I/O Bus	160mm	6U	Current, Voltage	6
23021-002	VMEbus	C96, System Bus	220mm	3U	Current, Voltage	6

Katalognummer	Type	ConnectorType	Board Depth	Rack Height	MeasuringField	Number of Layers
23021-100	VMEbus	C96, I/O Bus	160mm	3U	Current, Voltage	6
23021-001	VMEbus	C96, System Bus	160mm	3U	Current, Voltage	6
23021-101	VMEbus	C96, I/O Bus	220mm	3U	Current, Voltage	6
23022-010	VMEbus	C96, System Bus, C96, I/O Bus	280mm	6U	Current, Voltage	6
23022-004	VMEbus	C96, System Bus, C96, I/O Bus	220mm	6U	Current, Voltage	6

Table 2/2

Katalognummer	Pakke mængde	Hurtigforsendelse
23022-002	1	Nej
23021-002	1	Nej
23021-100	1	Nej
23021-001	1	Nej
23021-101	1	Nej
23022-010	1	Nej
23022-004	1	Nej

YDERLIGERE PRODUKTOPLYSNINGER

For 9 U VMEbus test Adapter solution see Intermediate Adaptor Adaptor Bracket, 9 U, 220 mm, 350 mm.

P1 = System Bus, P2 = I/O Bus.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl,

materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE