


U-profile Front Panel, Shieldable, D-Sub Cutouts

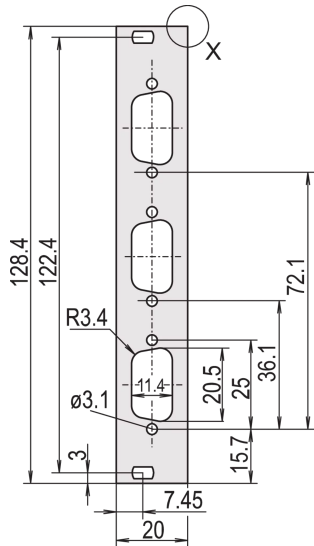

U-profile front panel with cutout for D-Sub connectors.
Shieldable for textile EMC gasket.

CERTIFICERINGER



FUNKTIONER

U-profile, front panel, Al, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

SPECIFIKATIONER

Dybde (D):	2.5mm
Rack Height:	3U
Rack Width:	4HP
Materiale:	Aluminium
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel without Handle

Table 1/2

Katalognummer	Pakke mængde	Mounting	EMC Gasket Type	Front Finish	Rear Finish	Number of Pins
30849-749	1	Screw-on Front	Textile	Anodized	Conductive	(1) 9
30849-750	1	Screw-on Front	Textile	Anodized	Conductive	(2) 9
30849-751	1	Screw-on Front	Textile	Anodized	Conductive	(3) 9
30849-752	1	Screw-on Front	Textile	Anodized	Conductive	(1) 15
30849-753	1	Screw-on Front	Textile	Anodized	Conductive	(2) 15
30849-754	1	Screw-on Front	Textile	Anodized	Conductive	(1) 25
30849-755	1	Screw-on Front	Textile	Anodized	Conductive	(2) 25

Table 2/2

Katalognummer	Treated Edges	Complies With	Højde (H)	Bredde (W)	Hurtigforsendelse
30849-749	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej
30849-750	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej
30849-751	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej
30849-752	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej
30849-753	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej
30849-754	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej
30849-755	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej

YDERLIGERE PRODUKTOPLYSNINGER


Please order fixing material (sleeves, collar screws) separately.


Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

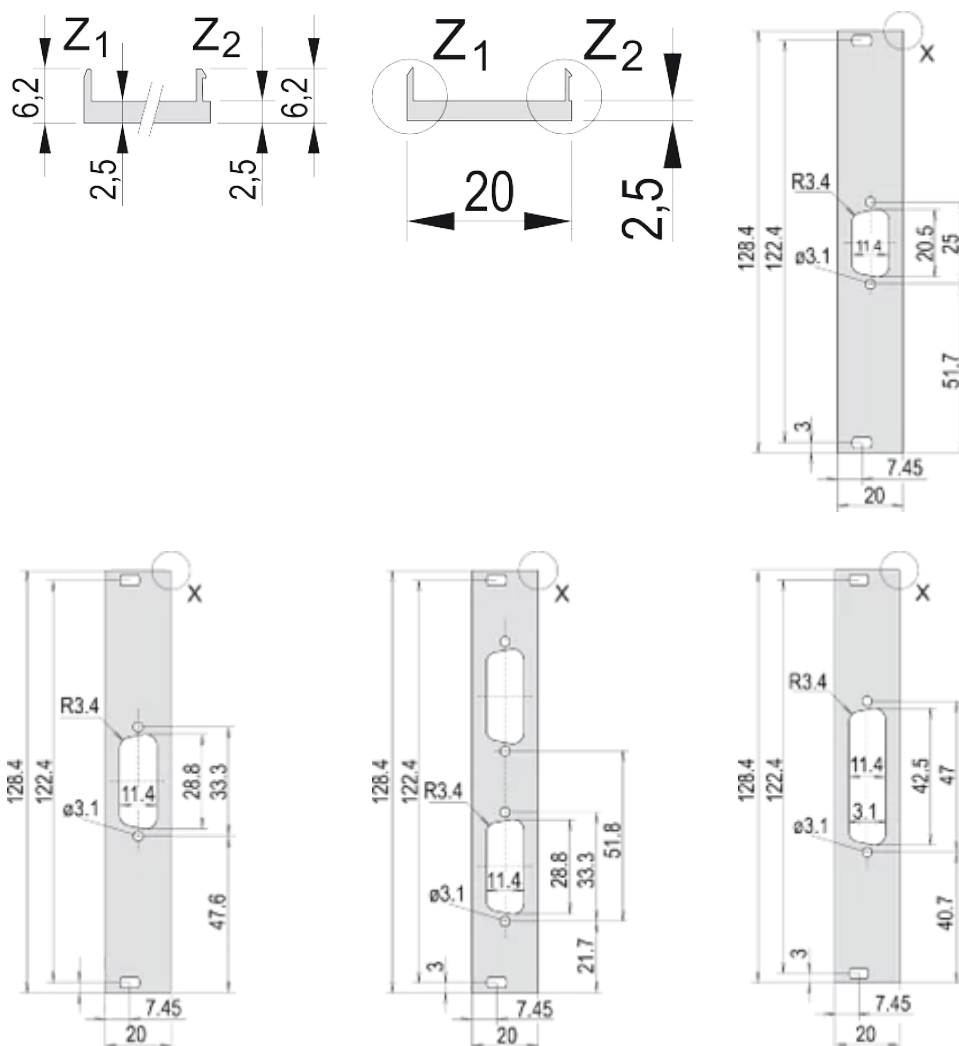

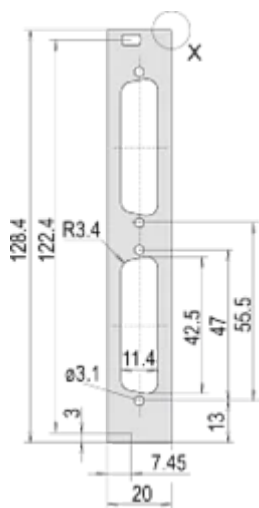

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE