


Varistar 19" Panel/Slide Mount

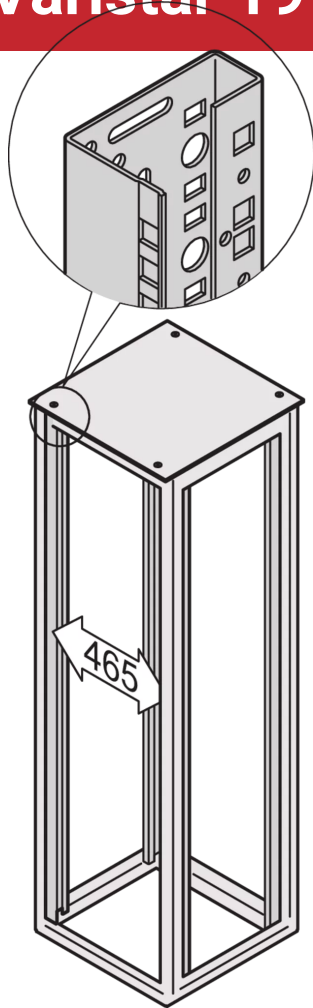

Slide mounts with adjustable increments.

CERTIFICERINGER



FUNKTIONER

Depth-adjustable in 25 mm increments

In accordance with IEC 60297-1 (DIN 41 494, Part 1)

Assembly in 600 mm wide cabinets directly on the frame

For 800 mm width adapter bracket for reduced width is necessary, for partial-height mounting depth members are necessary

Dimensions are engraved in U increments (1 ... 52 U)

Made of Steel, 2 mm thick

Subsequent assembly possible

SPECIFIKATIONER

Product Type: Slide Mount

Materiale: Stål

Table 1/2

Katalognummer	Rack Height	Højde	Finish	Pakke mængde	Farve	Farvekode
23130-037	8U	400mm	Aluminum-Zinc Plated	2		
23130-027	8U	400mm	Struktur Pulvermaling	2	Light Grey	RAL 7035
23130-017	8U	400mm	Struktur Pulvermaling	2	Black Grey	RAL 7021
23130-011	24U	1200mm	Struktur Pulvermaling	2	Black Grey	RAL 7021
23130-012	29U	1400mm	Struktur Pulvermaling	2	Black Grey	RAL 7021
23130-013	33U	1600mm	Struktur Pulvermaling	2	Black Grey	RAL 7021
23130-014	38U	1800mm	Struktur Pulvermaling	2	Black Grey	RAL 7021
23130-015	42U	2000mm	Struktur Pulvermaling	2	Black Grey	RAL 7021
23130-016	47U	2200mm	Struktur Pulvermaling	2	Black Grey	RAL 7021
23130-018	12U	550mm	Struktur Pulvermaling	2	Black Grey	RAL 7021
23130-019	16U	750mm	Struktur Pulvermaling	2	Black Grey	RAL 7021
23130-020	20U	900mm	Struktur Pulvermaling	2	Black Grey	RAL 7021
23130-021	24U	1200mm	Struktur Pulvermaling	2	Light Grey	RAL 7035

Katalognummer	Rack Height	Højde	Finish	Pakke mængde	Farve	Farvekode
23130-022	29U	1400mm	Struktur Pulvermaling	2	Light Grey	RAL 7035
23130-023	33U	1600mm	Struktur Pulvermaling	2	Light Grey	RAL 7035
23130-024	38U	1800mm	Struktur Pulvermaling	2	Light Grey	RAL 7035
23130-025	42U	2000mm	Struktur Pulvermaling	2	Light Grey	RAL 7035
23130-026	47U	2200mm	Struktur Pulvermaling	2	Light Grey	RAL 7035
23130-028	12U	550mm	Struktur Pulvermaling	2	Light Grey	RAL 7035
23130-029	16U	750mm	Struktur Pulvermaling	2	Light Grey	RAL 7035
23130-030	20U	900mm	Struktur Pulvermaling	2	Light Grey	RAL 7035
23130-031	24U	1200mm	Aluminum-Zinc Plated	2		
23130-032	29U	1400mm	Aluminum-Zinc Plated	2		
23130-033	33U	1600mm	Aluminum-Zinc Plated	2		
23130-034	38U	1800mm	Aluminum-Zinc Plated	2		
23130-035	42U	2000mm	Aluminum-Zinc Plated	2		
23130-036	47U	2200mm	Aluminum-Zinc Plated	2		
23130-038	12U	550mm	Aluminum-Zinc Plated	2		
23130-039	16U	750mm	Aluminum-Zinc Plated	2		
23130-040	20U	900mm	Aluminum-Zinc Plated	2		
23130-570	52U	2450mm	Struktur Pulvermaling	2	Black Grey	RAL 7021

Katalognummer	Rack Height	Højde	Finish	Pakke mængde	Farve	Farvekode
23130-588	52U	2450mm	Aluminum-Zinc Plated	2	Black Grey	RAL 7021

Table 2/2

Katalognummer	Length	Pakkeenhed	Hurtigforsendelse
23130-037	395mm		Nej
23130-027	395mm		Nej
23130-017	395mm		Nej
23130-011	1095mm	Pair	Nej
23130-012	1295mm	Pair	Nej
23130-013	1495mm		Nej
23130-014	1695mm	Pair	Nej
23130-015	1895mm	Pair	Nej
23130-016	2095mm	Pair	Nej
23130-018	545mm		Nej
23130-019	745mm		Nej
23130-020	895mm		Nej
23130-021	1095mm		Nej
23130-022	1295mm		Nej
23130-023	1495mm		Nej
23130-024	1695mm		Nej

Katalognummer	Length	Pakkeenhed	Hurtigforsendelse
23130-025	1895mm		Nej
23130-026	2095mm		Nej
23130-028	545mm		Nej
23130-029	745mm		Nej
23130-030	895mm		Nej
23130-031	1095mm	Pair	Nej
23130-032	1295mm	Pair	Nej
23130-033	1495mm		Nej
23130-034	1695mm	Pair	Nej
23130-035	1895mm	Pair	Nej
23130-036	2095mm	Pair	Nej
23130-038	545mm		Nej
23130-039	745mm		Nej
23130-040	895mm		Nej
23130-570	2345mm		Nej
23130-588	2345mm		Nej

YDERLIGERE PRODUKTOPLYSNINGER

For 19" partial-height mounting depth members are necessary.

Metric panel/slide mounts available on request.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE