


# Varistar CP Frame

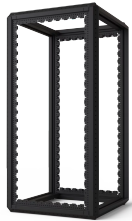

Varistar CP welded frame is available for static load requirements and can be integrated with 19", ETSI or mounting plate. Additionally, castors can be added to the frame if needed.

However, if you require castors for your application, you might want to consider a mobile frame that already includes castors.

## FUNKTIONER

Welded, finish powder-coated, black gray, RAL 7021

St, 1.5 mm, zinc-plated, with central GND/grounding point

Static load-carrying capacity max. 1600 kg

Please order adjustable feet separately

## SPECIFIKATIONER

**Static Load:** 1600kg  
**Product Type:** Cabinet/Rack Frame  
**Materiale:** Stål

Table 1/2

| Katalognummer | Rack Height | Højde  | Bredde | Dybde | Pakke mængde | Farve      |
|---------------|-------------|--------|--------|-------|--------------|------------|
| 20630-065     | 24U         | 1200mm | 600mm  | 600mm | 1            | Black Grey |
| 20630-066     | 24U         | 1200mm | 600mm  | 800mm | 1            | Black Grey |
| 20630-071     | 24U         | 1200mm | 800mm  | 600mm | 1            | Black Grey |
| 20630-072     | 24U         | 1200mm | 800mm  | 800mm | 1            | Black Grey |
| 20630-075     | 29U         | 1400mm | 600mm  | 600mm | 1            | Black Grey |

| Katalognummer | Rack Height | Højde  | Bredde | Dybde  | Pakke mængde | Farve      |
|---------------|-------------|--------|--------|--------|--------------|------------|
| 20630-076     | 29U         | 1400mm | 600mm  | 800mm  | 1            | Black Grey |
| 20630-079     | 29U         | 1400mm | 800mm  | 600mm  | 1            | Black Grey |
| 20630-080     | 29U         | 1400mm | 800mm  | 800mm  | 1            | Black Grey |
| 20630-083     | 33U         | 1600mm | 600mm  | 600mm  | 1            | Black Grey |
| 20630-084     | 33U         | 1600mm | 600mm  | 800mm  | 1            | Black Grey |
| 20630-087     | 33U         | 1600mm | 800mm  | 600mm  | 1            | Black Grey |
| 20630-088     | 33U         | 1600mm | 800mm  | 800mm  | 1            | Black Grey |
| 20630-091     | 38U         | 1800mm | 600mm  | 600mm  | 1            | Black Grey |
| 20630-092     | 38U         | 1800mm | 600mm  | 800mm  | 1            | Black Grey |
| 20630-095     | 38U         | 1800mm | 800mm  | 600mm  | 1            | Black Grey |
| 20630-096     | 38U         | 1800mm | 800mm  | 800mm  | 1            | Black Grey |
| 20630-261     | 42U         | 2000mm | 600mm  | 300mm  | 1            | Black Grey |
| 20630-099     | 42U         | 2000mm | 600mm  | 600mm  | 1            | Black Grey |
| 20630-100     | 42U         | 2000mm | 600mm  | 800mm  | 1            | Black Grey |
| 20630-101     | 42U         | 2000mm | 600mm  | 900mm  | 1            | Black Grey |
| 20630-102     | 42U         | 2000mm | 600mm  | 1000mm | 1            | Black Grey |
| 20630-105     | 42U         | 2000mm | 800mm  | 600mm  | 1            | Black Grey |
| 20630-106     | 42U         | 2000mm | 800mm  | 800mm  | 1            | Black Grey |

| Katalognummer | Rack Height | Højde  | Bredde | Dybde  | Pakke mængde | Farve      |
|---------------|-------------|--------|--------|--------|--------------|------------|
| 20630-107     | 42U         | 2000mm | 800mm  | 900mm  | 1            | Black Grey |
| 20630-108     | 42U         | 2000mm | 800mm  | 1000mm | 1            | Black Grey |
| 20630-262     | 47U         | 2200mm | 600mm  | 300mm  | 1            | Black Grey |
| 20630-111     | 47U         | 2200mm | 600mm  | 600mm  | 1            | Black Grey |
| 20630-112     | 47U         | 2200mm | 600mm  | 800mm  | 1            | Black Grey |
| 20630-113     | 47U         | 2200mm | 600mm  | 900mm  | 1            | Black Grey |
| 20630-114     | 47U         | 2200mm | 600mm  | 1000mm | 1            | Black Grey |
| 20630-117     | 47U         | 2200mm | 800mm  | 600mm  | 1            | Black Grey |
| 20630-118     | 47U         | 2200mm | 800mm  | 800mm  | 1            | Black Grey |
| 20630-119     | 47U         | 2200mm | 800mm  | 900mm  | 1            | Black Grey |
| 20630-120     | 47U         | 2200mm | 800mm  | 1000mm | 1            | Black Grey |
| 20630-067     | 24U         | 1200mm | 600mm  | 900mm  | 1            | Black Grey |
| 20630-068     | 24U         | 1200mm | 600mm  | 1000mm | 1            | Black Grey |
| 20630-073     | 24U         | 1200mm | 800mm  | 900mm  | 1            | Black Grey |
| 20630-074     | 24U         | 1200mm | 800mm  | 1000mm | 1            | Black Grey |
| 20630-077     | 29U         | 1400mm | 600mm  | 900mm  | 1            | Black Grey |
| 20630-078     | 29U         | 1400mm | 600mm  | 1000mm | 1            | Black Grey |
| 20630-081     | 29U         | 1400mm | 800mm  | 900mm  | 1            | Black Grey |

| Katalognummer | Rack Height | Højde  | Bredde | Dybde  | Pakke mængde | Farve      |
|---------------|-------------|--------|--------|--------|--------------|------------|
| 20630-082     | 29U         | 1400mm | 800mm  | 1000mm | 1            | Black Grey |
| 20630-085     | 33U         | 1600mm | 600mm  | 900mm  | 1            | Black Grey |
| 20630-086     | 33U         | 1600mm | 600mm  | 1000mm | 1            | Black Grey |
| 20630-089     | 33U         | 1600mm | 800mm  | 900mm  | 1            | Black Grey |
| 20630-090     | 33U         | 1600mm | 800mm  | 1000mm | 1            | Black Grey |
| 20630-093     | 38U         | 1800mm | 600mm  | 900mm  | 1            | Black Grey |
| 20630-094     | 38U         | 1800mm | 600mm  | 1000mm | 1            | Black Grey |
| 20630-097     | 38U         | 1800mm | 800mm  | 900mm  | 1            | Black Grey |
| 20630-098     | 38U         | 1800mm | 800mm  | 1000mm | 1            | Black Grey |
| 20630-123     | 52U         | 2450mm | 600mm  | 1000mm | 1            | Black Grey |
| 20630-126     | 52U         | 2450mm | 800mm  | 1000mm | 1            | Black Grey |
| 20630-125     | 52U         | 2450mm | 600mm  | 1200mm | 1            | Black Grey |
| 20630-128     | 52U         | 2450mm | 800mm  | 1200mm | 1            | Black Grey |
| 20630-124     | 52U         | 2450mm | 600mm  | 1100mm | 1            | Black Grey |
| 20630-127     | 52U         | 2450mm | 800mm  | 1100mm | 1            | Black Grey |
| 20630-103     | 42U         | 2000mm | 600mm  | 1100mm | 1            | Black Grey |
| 20630-104     | 42U         | 2000mm | 600mm  | 1200mm | 1            | Black Grey |
| 20630-109     | 42U         | 2000mm | 800mm  | 1100mm | 1            | Black Grey |

| Katalognummer | Rack Height | Højde  | Bredde | Dybde  | Pakke mængde | Farve      |
|---------------|-------------|--------|--------|--------|--------------|------------|
| 20630-110     | 42U         | 2000mm | 800mm  | 1200mm | 1            | Black Grey |
| 20630-115     | 47U         | 2200mm | 600mm  | 1100mm | 1            | Black Grey |
| 20630-116     | 47U         | 2200mm | 600mm  | 1200mm | 1            | Black Grey |
| 20630-121     | 47U         | 2200mm | 800mm  | 1100mm | 1            | Black Grey |
| 20630-122     | 47U         | 2200mm | 800mm  | 1200mm | 1            | Black Grey |

Table 2/2

| Katalognummer | Farvekode | Complies With | Frame Material | Type     | Works With  | Hurtigforsendelse |
|---------------|-----------|---------------|----------------|----------|-------------|-------------------|
| 20630-065     | RAL 7021  |               | Stål           | Standard | Varistar CP | Nej               |
| 20630-066     | RAL 7021  |               | Stål           | Standard | Varistar CP | Nej               |
| 20630-071     | RAL 7021  |               | Stål           | Standard | Varistar CP | Nej               |
| 20630-072     | RAL 7021  |               | Stål           | Standard | Varistar CP | Nej               |
| 20630-075     | RAL 7021  |               | Stål           | Standard | Varistar CP | Nej               |
| 20630-076     | RAL 7021  |               | Stål           | Standard | Varistar CP | Nej               |
| 20630-079     | RAL 7021  |               | Stål           | Standard | Varistar CP | Nej               |
| 20630-080     | RAL 7021  |               | Stål           | Standard | Varistar CP | Nej               |
| 20630-083     | RAL 7021  |               | Stål           | Standard | Varistar CP | Nej               |
| 20630-084     | RAL 7021  |               | Stål           | Standard | Varistar CP | Nej               |
| 20630-087     | RAL 7021  |               | Stål           | Standard | Varistar CP | Nej               |

| Katalognummer | Farvekode | Complies With               | Frame Material | Type     | Works With  | Hurtigforsendelse |
|---------------|-----------|-----------------------------|----------------|----------|-------------|-------------------|
| 20630-088     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-091     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-092     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-095     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-096     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-261     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-099     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-100     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-101     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-102     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-105     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-106     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-107     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-108     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-262     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-111     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-112     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-113     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |

| Katalognummer | Farvekode | Complies With               | Frame Material | Type     | Works With  | Hurtigforsendelse |
|---------------|-----------|-----------------------------|----------------|----------|-------------|-------------------|
| 20630-114     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-117     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-118     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-119     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-120     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-067     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-068     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-073     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-074     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-077     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-078     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-081     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-082     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-085     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-086     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-089     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-090     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-093     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |

| Katalognummer | Farvekode | Complies With               | Frame Material | Type     | Works With  | Hurtigforsendelse |
|---------------|-----------|-----------------------------|----------------|----------|-------------|-------------------|
| 20630-094     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-097     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-098     | RAL 7021  |                             | Stål           | Standard | Varistar CP | Nej               |
| 20630-123     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-126     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-125     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-128     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-124     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-127     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-103     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-104     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-109     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-110     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-115     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-116     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-121     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |
| 20630-122     | RAL 7021  | IEC 61587-1,<br>IEC 61587-3 | Stål           | Standard | Varistar CP | Nej               |



## YDERLIGERE PRODUKTOPLYSNINGER

Castor can be added to the frame. If you will need a castor for your application, you can order a mobile frame which include castors.

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**