


VME64x Backplane

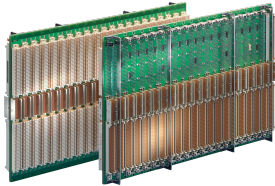

The nVent SCHROFF VME64x Backplanes have outstanding high-frequency noise suppression and very high MTBF values due to ceramic capacitors and SMD fabrication technology.

CERTIFICERINGER



FUNKTIONER

In accordance with ANSI/VITA 1-1994 VME64 Standard, ANSI/VITA 1.1-1997 VME64 Extension Standard, ANSI/VITA 1.5-2003 VME2eSST Specification, ANSI/VITA 1.7-2003 Increased Current Level, ANSI/VITA 38 System Management on VME

Monolithic backplane, 6 U with J1 and J2 plane

Connection or isolation between the digital GND and chassis GND can be changed via screw

Termination passive

Electronic automatic daisy chain (EDC)

Supply voltages can be applied via powerbugs (ring tag M4) or FASTON

Utility connector for status signals

Connector for additional voltages V1/V2

System management bus (SMB) connector in accordance with VITA38

SPECIFIKATIONER

Table 1/2

Katalognummer	Product Type	Number of Slots	Rack Height	Backplane Type	System Slot	Slot Width
---------------	--------------	-----------------	-------------	----------------	-------------	------------

23001-502	Backplane	2	6U	VME64x with EDC	Slot 1 Left	4HP
23001-503	Backplane	3	6U	VME64x with EDC	Slot 1 Left	4HP
23001-504	Backplane	4	6U	VME64x with EDC	Slot 1 Left	4HP
23001-505	Backplane	5	6U	VME64x with EDC	Slot 1 Left	4HP
23001-506	Backplane	6	6U	VME64x with EDC	Slot 1 Left	4HP
23001-507	Backplane	7	6U	VME64x with EDC	Slot 1 Left	4HP
23001-508	Backplane	8	6U	VME64x with EDC	Slot 1 Left	4HP
23001-510	Backplane	10	6U	VME64x with EDC	Slot 1 Left	4HP
23001-511	Backplane	11	6U	VME64x with EDC	Slot 1 Left	4HP
23001-512	Backplane	12	6U	VME64x with EDC	Slot 1 Left	4HP
23001-515	Backplane	15	6U	VME64x with EDC	Slot 1 Left	4HP
23001-516	Backplane	16	6U	VME64x with EDC	Slot 1 Left	4HP
23001-520	Backplane	20	6U	VME64x with EDC	Slot 1 Left	4HP
23001-521	Backplane	21	6U	VME64x with EDC	Slot 1 Left	4HP
23001-532	Backplane	2	6U	VME64x with EDC	Slot 1 Left	4HP
23001-533	Backplane	3	6U	VME64x with EDC	Slot 1 Left	4HP
23001-534	Backplane	4	6U	VME64x with EDC	Slot 1 Left	4HP
23001-535	Backplane	5	6U	VME64x with EDC	Slot 1 Left	4HP
23001-536	Backplane	6	6U	VME64x with EDC	Slot 1 Left	4HP

23001-537	Backplane	7	6U	VME64x with EDC	Slot 1 Left	4HP
23001-538	Backplane	8	6U	VME64x with EDC	Slot 1 Left	4HP
23001-540	Backplane	10	6U	VME64x with EDC	Slot 1 Left	4HP
23001-541	Backplane	11	6U	VME64x with EDC	Slot 1 Left	4HP
23001-542	Backplane	12	6U	VME64x with EDC	Slot 1 Left	4HP
23001-545	Backplane	15	6U	VME64x with EDC	Slot 1 Left	4HP
23001-546	Backplane	16	6U	VME64x with EDC	Slot 1 Left	4HP
23001-550	Backplane	20	6U	VME64x with EDC	Slot 1 Left	4HP
23001-551	Backplane	21	6U	VME64x with EDC	Slot 1 Left	4HP

Table 2/2						
Katalognummer	Connector Type	Power Connector Type	Utility Connector Type	Bredde	Pakke mængde	Hurtigforsendelse
23001-502	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	39.1mm	1	Nej
23001-503	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	59.5mm	1	Nej
23001-504	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	79.8mm	1	Nej
23001-505	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	100.2mm	1	Nej
23001-506	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	120.5mm	1	Nej
23001-507	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	140.8mm	1	Nej
23001-508	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.1mm	1	Nej
23001-510	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	201.8mm	1	Nej

Katalognummer	ConnectorType	Power ConnectorType	Utility ConnectorType	Bredde	Pakke mængde	Hurtigforsendelse
23001-511	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	222mm	1	Nej
23001-512	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	242.4mm	1	Nej
23001-515	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	303.4mm	1	Nej
23001-516	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	323.7mm	1	Nej
23001-520	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	405mm	1	Nej
23001-521	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	425.3mm	1	Nej
23001-532	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	39.1mm	1	Nej
23001-533	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	59.5mm	1	Nej
23001-534	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	79.8mm	1	Nej
23001-535	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	100.2mm	1	Nej
23001-536	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	120.5mm	1	Nej
23001-537	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	140.8mm	1	Nej
23001-538	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.1mm	1	Nej
23001-540	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	201.8mm	1	Nej
23001-541	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	222mm	1	Nej
23001-542	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	242.4mm	1	Nej
23001-545	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	303.4mm	1	Nej
23001-546	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	323.7mm	1	Nej

Katalognummer	ConnectorType	Power ConnectorType	Utility ConnectorType	Bredde	Pakke mængde	Hurtigforsendelse
23001-550	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	405mm	1	Nej
23001-551	DIN 41612, VME64x	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	425.3mm	1	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Other configurations available on request.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE