

Horizontal Pouring Basin, Top Fill, 90°



90 degree top fill horizontal pouring basins are used when structural interferences are directly above the tap hole in the sleeve.

MERKMALE

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal top fill sleeves

SPEZIFIKATIONEN

Material: Graphit

Table 1/1

Katalognummer	Durchmesser (Ø)	Länge 1 (L1)	Länge 2 (L2)	Breite (W)	Höhe 1 (H1)	Höhe 2 (H2)
RB TSA9040X	38 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSA9735X	38 mm	248 mm	76 mm	76 mm	140mm	89mm
RB TSA6040F	64 mm	152 mm	76 mm	76 mm	140mm	102mm
RB TSA9740A	41 mm	248 mm	76 mm	76 mm	140mm	102mm
RB TSA7040J	76 mm	179 mm	76 mm	76 mm	140mm	102mm
RB TSA9040C	48 mm	229 mm	76 mm	76 mm	140mm	102mm


Katalognummer	Durchmesser (Ø)	Länge 1 (L1)	Länge 2 (L2)	Breite (W)	Höhe 1 (H1)	Höhe 2 (H2)
RB TSA9740C	48 mm	248 mm	76 mm	76 mm	140mm	102mm
RB TSA9040D	54 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSB15045D	54 mm	381 mm	76 mm	76 mm	152mm	114mm
RB TSB12040E	57 mm	305 mm	76 mm	76 mm	152mm	102mm
RB TSA9040F	64 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSB12042F	64 mm	305 mm	76 mm	76 mm	152mm	108mm
RB TSA9040J	76 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSB13545J	76 mm	342 mm	76 mm	76 mm	152mm	114mm
RB TSA9040M	95 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSB12050M	95 mm	305 mm	76 mm	76 mm	152mm	127mm
RB TSB15045M	95 mm	381 mm	76 mm	76 mm	152mm	114mm
RB TSB18550M	95 mm	470 mm	76 mm	76 mm	152mm	127mm
RB TSC18550M	95 mm	470 mm	76 mm	76 mm	179mm	127mm
RB TSC26050M	95 mm	660 mm	76 mm	76 mm	179mm	127mm

ZUSÄTZLICHE PRODUKTDDETAILS

RB TSA pouring basins require one RBW341 pouring basin frame. RB TSB and RB TSC pouring basins require one RBW341 pouring basin frame and two RBS5000 bolt retainers (all sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

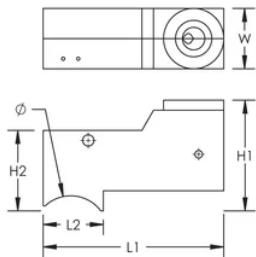

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.

Nordamerika

+1.800.753.9221

Option 1 – Kundendienst

Option 2 – Technischer

Support

Europa

Niederlande:

+31 800-0200135

Frankreich:

+33 800 901 793

Europa

Deutschland:

800 1890272

Sonstige Länder:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Unser starkes markenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE