

Vertical Pouring Basin, Extended



Extended vertical pouring basins are used when interferences of the structure are directly next to the tap hole in the sleeve.

MERKMALE

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series vertical sleeves

SPEZIFIKATIONEN

Material: Graphit

Table 1/1

Katalognummer	Durchmesser (Ø)	Länge 1 (L1)	Länge 2 (L2)	Breite (W)	Höhe 1 (H1)	Höhe 2 (H2)
RBVB11065X	38 mm	279 mm	38 mm	76 mm	165mm	76mm
RBVA7570J	76 mm	191 mm	38 mm	76 mm	178mm	76mm
RBVA9060F	64 mm	229 mm	38 mm	76 mm	152mm	76mm
RBVA9095F	64 mm	229 mm	38 mm	76 mm	241mm	76mm
RBVA9095M	95 mm	229 mm	38 mm	76 mm	241mm	76mm
RBVB12060E	57 mm	305 mm	38 mm	76 mm	152mm	76mm

Katalognummer	Durchmesser (Ø)	Länge 1 (L1)	Länge 2 (L2)	Breite (W)	Höhe 1 (H1)	Höhe 2 (H2)
RBVB12065F	64 mm	305 mm	38 mm	76 mm	165mm	76mm
RBVB12070M	95 mm	305 mm	38 mm	76 mm	178mm	76mm
RBVB14065F	64 mm	356 mm	38 mm	76 mm	165mm	76mm
RBVB14075M	95 mm	356 mm	38 mm	76 mm	191mm	76mm
RBVB14080J	64 mm	356 mm	38 mm	76 mm	203mm	76mm
RBVB16575E	95 mm	419 mm	38 mm	76 mm	191mm	76mm
RBVB16575J	76 mm	419 mm	38 mm	76 mm	191mm	76mm
RBVB16575M	95 mm	419 mm	38 mm	76 mm	191mm	76mm
RBVB17075D	76 mm	432 mm	38 mm	76 mm	191mm	76mm
RBVB17710F	64 mm	451 mm	38 mm	76 mm	254mm	76mm
RBVB17710M	95 mm	451 mm	38 mm	76 mm	254mm	76mm


ZUSÄTZLICHE PRODUKTDDETAILS

RBVA pouring basins require one RBM2660DC pouring basin frame and one RBS5000 bolt retainer. RBVB pouring basins require one RBM2660TC pouring basin frame and one RBS5000 bolt retainer (all sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMME

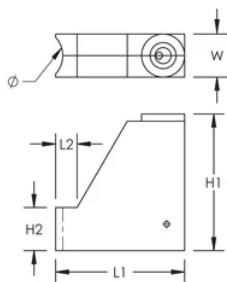

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.

Nordamerika

+1.800.753.9221

Option 1 – Kundendienst

Option 2 – Technischer

Support

Europa

Niederlande:

+31 800-0200135

Frankreich:

+33 800 901 793

Europa

Deutschland:

800 1890272

Sonstige Länder:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Unser starkes markenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE