


19" Pusher Fan, 3 U, Axial

Power Utilities

Fan tray with integrated pusher fan.

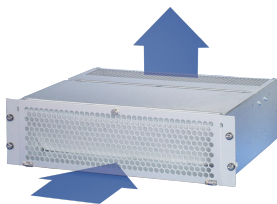

ZERTIFIZIERUNGEN



MERKMALE

Ventilation directed accurately to the electronics

19" Pusher Fan, 3 U, Axial

Air infeed from front, air exits at the top rear of cabinet (guided upwards by cover plates or via hoses to rear and upwards)

Contact protection in accordance with DIN EN ISO 13857

SPEZIFIKATIONEN

Table 1/1

Katalognummer	Eingangsspannung AC
10713-546	230 V min
10713-547	115 V min

ZUSÄTZLICHE PRODUKTDDETAILS

With cover plates, this pusher fan can be re-fitted to different cooling concepts

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Unser starkes markenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE