


Frame Type Plug-In Unit PRO Kit, With Hood, Shielded Version, 3 U, 7 HP, 227 mm

Power Utilities

KATALOGNUMMER

24813-057

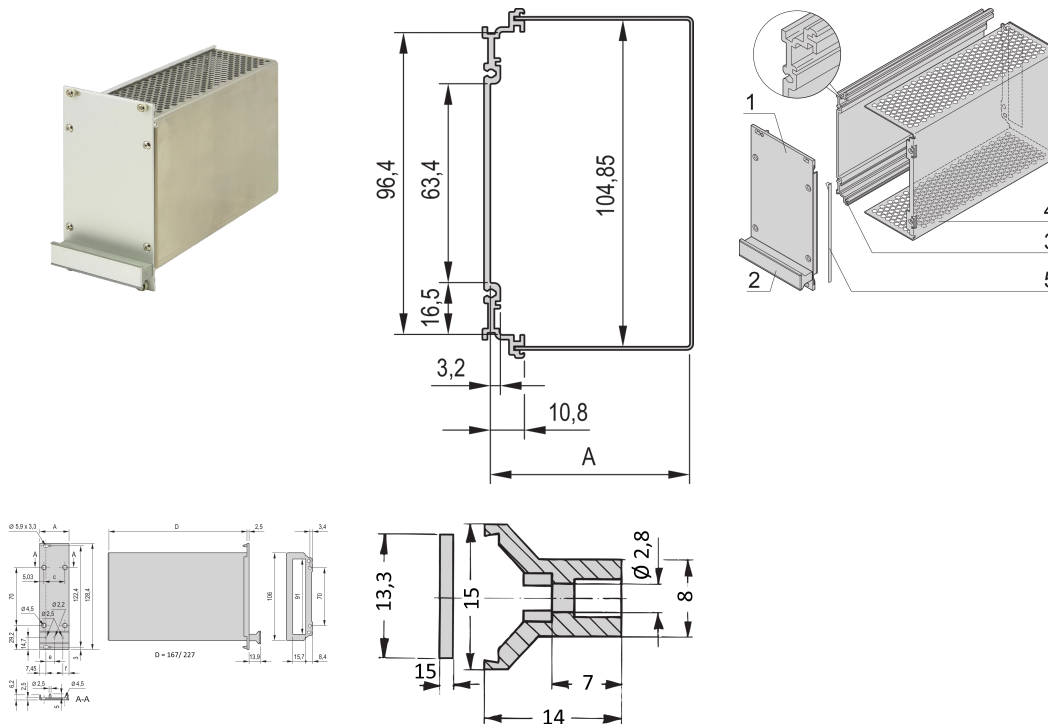

Protects a PCB against mechanical damage and discharges electrostatic buildup; for Euroboard formats.

ZERTIFIZIERUNGEN



MERKMALE

Fits all products conforming to IEC-60297-3-101

Protects a PCB against mechanical damage and discharges electrostatic buildup; for Euroboard formats

Connectors usable under EN 60603-2 (DIN 41612)

PRODUKTMERKMALE

Produkttyp: Kassette

Typ: Rahmentyp-Steckbaugruppen PRO mit Haube

Grifftyp: Trapezförmig

Höhe Gestell: 3 U

Breite Gestell: 7 HP

Tiefe: 227 mm

EMV-Schirmung: Ja

Typ EMV-Dichtung: Textil

Rückwandtyp: Ausbruch einzelner Steckverbinder

Abdeckblechtyp: Haube

Material: Aluminium

Frontbeschichtung: Eloxiert

Oberfläche Rückseite: Leitend

Kühlung: Perforiert

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Unser starkes markenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE