


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, SNCF

Power Utilities

Subrack for Railway applications, conform to SNCF Standard, non-shielded versions.

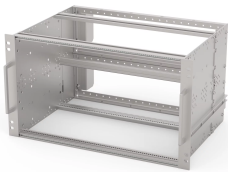

ZERTIFIZIERUNGEN



MERKMALE

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

SPEZIFIKATIONEN

Table 1/3

Katalognummer	Höhe Gestell	Breite Gestell	Tiefe	Anzahl Verpackungen	Zur Montage	Leiterplattentiefe
21500-070	6 U	36 HP	320 mm	1	Rückwandplatine	220 mm
21500-067	3 U	36 HP	320 mm	1	Rückwandplatine	220 mm
21500-029	3 U	84 HP	320 mm	1	Rückwandplatine	220 mm
21500-027	6 U	84 HP	320 mm	1	Rückwandplatine	220 mm

Table 2/3

Katalognummer	Typ Dichtung	Schock- und Vibrationstoleranz	Griff enthalten	Befestigung	Entspricht	EMV-Schirmung
21500-070	Textile	5 g (force)	Ja	Gestell	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Nein
21500-067	Textile	5 g (force)	Ja	Gestell	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Nein
21500-029	Textile	5 g (force)	Ja	Gestell	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Nein
21500-027	Textile	5 g (force)	Ja	Gestell	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Nein

Table 3/3

Katalognummer	Produkttyp	Statische Last	Zertifizierungen
21500-070	Baugruppenträger/Einschub	15 kgf	RoHS
21500-067	Baugruppenträger/Einschub	15 kgf	RoHS
21500-029	Baugruppenträger/Einschub	15 kgf	RoHS, SNCF

Katalognummer	Produkttyp	Statische Last	Zertifizierungen
21500-027	Baugruppenträger/Einschub	15 kgf	RoHS, SNCF

ZUSÄTZLICHE PRODUKTDDETAILS

Test reports are available online.

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Unser starkes markenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE