


Front Panel, Flat, Unshielded, D-Sub Cutouts

Energieversorger

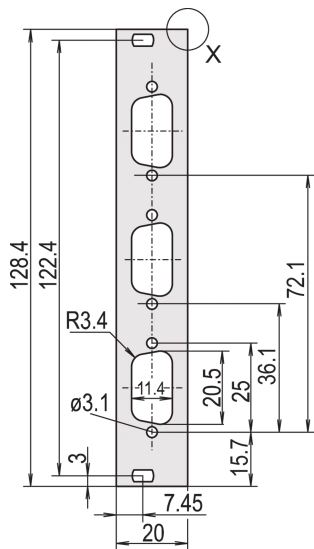

Flat front panel with cutout for D-Sub connectors.
Unshielded version.

ZERTIFIZIERUNGEN



EIGENSCHAFTEN

Non-shielded version

Aluminum, 2.5 mm, front anodized, rear conductive

SPEZIFIKATIONEN

Table 1/3						
Katalognummer	Package Quantity	Montage	Front Finish	Rear Finish	Treated Edges	Konform mit
30118-341	5	Screw-on Front	Anodized	Conductive	Nein	IEC 60297-3-101, IEEE 1101.1/10

Katalognummer	Package Quantity	Montage	Front Finish	Rear Finish	Treated Edges	Konform mit
30118-342	5	Screw-on Front	Anodized	Conductive	Nein	IEC 60297-3-101, IEEE 1101.1/10
30118-343	5	Screw-on Front	Anodized	Conductive	Nein	IEC 60297-3-101, IEEE 1101.1/10
30118-344	5	Screw-on Front	Anodized	Conductive	Nein	IEC 60297-3-101, IEEE 1101.1/10
30118-345	5	Screw-on Front	Anodized	Conductive	Nein	IEC 60297-3-101, IEEE 1101.1/10
30118-346	5	Screw-on Front	Anodized	Conductive	Nein	IEC 60297-3-101, IEEE 1101.1/10
30118-347	5	Screw-on Front	Anodized	Conductive	Nein	IEC 60297-3-101, IEEE 1101.1/10

Table 2/3

Katalognummer	EMC Shielding	Höhe	Material	Product Type	Rack Height	Rack Width
30118-341	Nein	128.4 mm	Aluminium	Frontplatte	3 U	4 HP
30118-342	Nein	128.4 mm	Aluminium	Frontplatte	3 U	4 HP
30118-343	Nein	128.4 mm	Aluminium	Frontplatte	3 U	4 HP
30118-344	Nein	128.4 mm	Aluminium	Frontplatte	3 U	4 HP
30118-345	Nein	128.4 mm	Aluminium	Frontplatte	3 U	4 HP
30118-346	Nein	128.4 mm	Aluminium	Frontplatte	3 U	4 HP
30118-347	Nein	128.4 mm	Aluminium	Frontplatte	3 U	4 HP

Table 3/3

Katalognummer	Typ	Breite
30118-341	Front Panel without Handle	20 mm

Katalognummer	Typ	Breite
30118-342	Front Panel without Handle	20 mm
30118-343	Front Panel without Handle	20 mm
30118-344	Front Panel without Handle	20 mm
30118-345	Front Panel without Handle	20 mm
30118-346	Front Panel without Handle	20 mm
30118-347	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE