


Frontplatte für HF-Kassetten, Nachrüstbare EMC Schirmung mit Stahldichtung, 3 HE, 28 TE

KATALOGNUMMER

20838-098

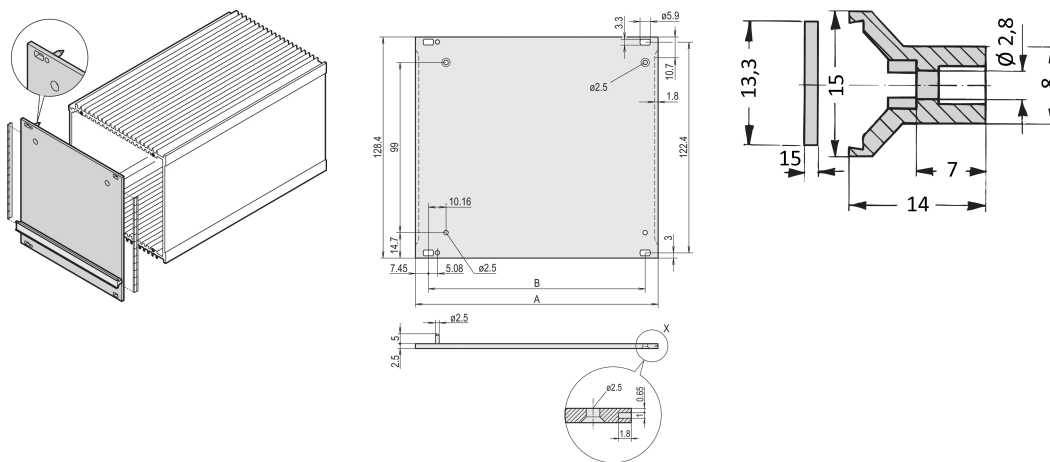

Al, 2,5 mm, Frontseite eloxiert, Rückseite leitend, mit seitlichen Slots für eine EMV-Dichtung aus Edelstahl (bitte separat bestellen), eingepresster Ausrichtungsstift; trapezförmiger Griff, grau, PPE, UL 94 V-1.

ZERTIFIZIERUNGEN



MERKMALE

Al, 2,5 mm, Frontseite eloxiert, Rückseite leitfähig, mit seitlichen Schlitten für EMV-Dichtung (Stahl, rostfrei (bitte separat bestellen)), pressed-in alignment pin; trapezium shaped handle, grau, PPE, UL 94 V-1

Frontplatte mit Griff zum Anschrauben an HF-Kassette

PRODUKTMERKMALE

Breite Gestell: 28HP

Anzahl Verpackungen: 1

Oberfläche: Eloxiert; Passiviert

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Unser starkes markenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE