


EuropacPRO Mounting Plate for Use With Cover Plate

Energieversorger

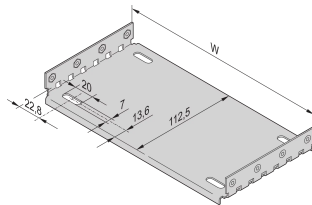

Mounting plate for use with cover plates for installation and fixing of heavy components. Full width mounting plates (as wide as the subrack or the system case) are fixed to the side panels. The partial width mounting plates are fixed to the side panel and horizontal rail by means of an assembly strip.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

ZERTIFIZIERUNGEN



EIGENSCHAFTEN

For installation and fixing of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

A guide rail can be fitted in first and last slot position

In addition to the mounting plate EMC cover plates can also be fitted to the subrack

Guide rails type 4.4 and "strengthened" cannot be used

SPEZIFIKATIONEN

Table 1/2

Katalognummer	Rack Width	Package Quantity	Tiefe	Material	Product Family	Product Type
34563-019	63 HP	1	172.5 mm	Aluminium	EuropacPRO	Mounting Plate

Katalognummer	Rack Width	Package Quantity	Tiefe	Material	Product Family	Product Type
34563-001	28 HP	1	112.5 mm	Aluminium	EuropacPRO	Mounting Plate
34563-003	63 HP	1	112.5 mm	Aluminium	EuropacPRO	Mounting Plate
34563-044	84 HP	1	412.5 mm	Aluminium	EuropacPRO	Mounting Plate
34563-042	84 HP	1	352.5 mm	Aluminium	EuropacPRO	Mounting Plate
34563-009	28 HP	1	172.5 mm	Aluminium	EuropacPRO	Mounting Plate
34563-002	42 HP	1	112.5 mm	Aluminium	EuropacPRO	Mounting Plate
34563-028	84 HP	1	292.5 mm	Aluminium	EuropacPRO	Mounting Plate
34563-026	84 HP	1	232.5 mm	Aluminium	EuropacPRO	Mounting Plate
34563-014	42 HP	1	172.5 mm	Aluminium	EuropacPRO	Mounting Plate
34563-024	84 HP	1	172.5 mm	Aluminium	EuropacPRO	Mounting Plate
34563-004	84 HP	1	112.5 mm	Aluminium	EuropacPRO	Mounting Plate

Table 2/2			
Katalognummer	Breite	Kompatibel mit	Zertifizierungen
34563-019	324.67 mm	Baugruppenträger	RoHS
34563-001	146.88 mm	Baugruppenträger	RoHS
34563-003	324.67 mm	Baugruppenträger	RoHS
34563-044	431.35 mm	Baugruppenträger	
34563-042	431.35 mm	Baugruppenträger	
34563-009	146.88 mm	Baugruppenträger	RoHS

Katalognummer	Breite	Kompatibel mit	Zertifizierungen
34563-002	217.99 mm	Baugruppenträger	RoHS
34563-028	431.35 mm	Baugruppenträger	
34563-026	431.35 mm	Baugruppenträger	
34563-014	217.99 mm	Baugruppenträger	RoHS
34563-024	431.35 mm	Baugruppenträger	RoHS
34563-004	431.35 mm	Baugruppenträger	RoHS

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE