


Novastar Base/Plinth

Energieversorger

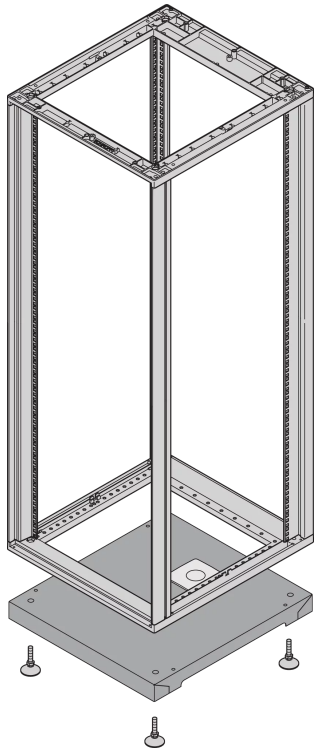

Base Plate for Rear Cable Ducting which cut out for cable management. Opening is covered with plastic. Accessory brush strip can build in.

ZERTIFIZIERUNGEN



EIGENSCHAFTEN

Static load-carrying capacity 400 kg

Adjustable feet, height 57 mm ... 67 mm

St, 1.5 mm, RAL 7021

Cable ducting 110 x 76 mm

Incl. GND/earthing

SPEZIFIKATIONEN

Table 1/2

Katalognummer	Breite	Tiefe	Farbe	Color Code	Höhe	Product Type
27230-070	553 mm	500 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-071	553 mm	600 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-072	553 mm	800 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-076	900 mm	900 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-080	1000 mm	1000 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base

Table 2/2

Katalognummer	Typ
27230-070	Base Plinth
27230-071	Base Plinth
27230-072	Base Plinth
27230-076	Base Plinth
27230-080	Base Plinth

ADDITIONAL PRODUCT DETAILS

Please order brush strip separately.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE