

# A12 Standard Transition Coupler, Plain, Worldwide Design



## ZERTIFIZIERUNGEN



## MERKMALE

Designed to splice different diameter bars where the second bar can be rotated and is not restricted in its axial direction

Slim design maintains concrete cover

Installs quickly and easily

## SPEZIFIKATIONEN

|                           |                                        |
|---------------------------|----------------------------------------|
| <b>Oberfläche:</b>        | Blank                                  |
| <b>Material:</b>          | Stahl                                  |
| <b>Auslegungsversion:</b> | Weltweit (global verfügbares Material) |

Table 1/2

| Katalognummer | Bewehrungssta<br>bgröße,<br>metrisch | Größe<br>Armierung,<br>USA | Größe<br>Armierung,<br>Kanada | Sechskant-<br>Breite (W) | Durchmesser<br>(Ø) | Länge (L) |
|---------------|--------------------------------------|----------------------------|-------------------------------|--------------------------|--------------------|-----------|
|---------------|--------------------------------------|----------------------------|-------------------------------|--------------------------|--------------------|-----------|

|            |              |        |          |       |  |      |
|------------|--------------|--------|----------|-------|--|------|
| EL1210A12N | 12 mm, 10 mm | #4, #3 |          | 17 mm |  | 55mm |
| EL1412A12N | 14 mm, 12 mm |        |          | 22 mm |  | 57mm |
| EL1612A12N | 16 mm, 12 mm | #5, #4 | 15M, 10M | 22 mm |  | 61mm |
| EL1614A12N | 16 mm, 14 mm |        |          | 22 mm |  | 64mm |
| EL1410A12N | 14 mm, 10 mm |        |          | 22 mm |  | 57mm |
| EL1610A12N | 16 mm, 10 mm | #5, #3 |          | 22 mm |  | 61mm |
| EL1810A12N | 18 mm, 10 mm |        |          | 27 mm |  | 66mm |
| EL1812A12N | 18 mm, 12 mm |        |          | 27 mm |  | 66mm |
| EL1814A12N | 18 mm, 14 mm |        |          | 27 mm |  | 69mm |
| EL1816A12N | 18 mm, 16 mm |        |          | 27 mm |  | 71mm |
| EL2012A12N | 20 mm, 12 mm | #6, #4 | 20M, 10M | 27 mm |  | 74mm |
| EL2010A12N | 20 mm, 10 mm | #6, #3 |          | 27 mm |  | 74mm |
| EL2014A12N | 20 mm, 14 mm |        |          | 27 mm |  | 77mm |
| EL2016A12N | 20 mm, 16 mm | #6, #5 | 20M, 15M | 27 mm |  | 80mm |
| EL2018A12N | 20 mm, 18 mm |        |          | 27 mm |  | 85mm |
| EL2212A12N | 22 mm, 12 mm | #7, #4 |          | 30 mm |  | 77mm |
| EL2210A12N | 22 mm, 10 mm | #7, #3 |          | 30 mm |  | 77mm |
| EL2214A12N | 22 mm, 14 mm |        |          | 30 mm |  | 80mm |
| EL2216A12N | 22 mm, 16 mm | #7, #5 |          | 30 mm |  | 83mm |

|            |              |        |          |       |       |       |
|------------|--------------|--------|----------|-------|-------|-------|
| EL2218A12N | 22 mm, 18 mm |        |          | 30 mm |       | 87mm  |
| EL2220A12N | 22 mm, 20 mm | #7, #6 |          | 30 mm |       | 95mm  |
| EL2512A12N | 25 mm, 12 mm | #8, #4 | 25M, 10M |       | 35 mm | 81mm  |
| EL2510A12N | 25 mm, 10 mm | #8, #3 |          |       | 35 mm | 81mm  |
| EL2514A12N | 25 mm, 14 mm |        |          |       | 35 mm | 83mm  |
| EL2516A12N | 25 mm, 16 mm | #8, #5 | 25M, 15M |       | 35 mm | 86mm  |
| EL2518A12N | 25 mm, 18 mm |        |          |       | 35 mm | 90mm  |
| EL2522A12N | 25 mm, 22 mm | #8, #7 |          |       | 35 mm | 100mm |
| EL2520A12N | 25 mm, 20 mm | #8, #6 | 25M, 20M |       | 35 mm | 98mm  |
| EL2814A12N | 28 mm, 14 mm |        |          |       | 40 mm | 86mm  |
| EL2816A12N | 28 mm, 16 mm | #9, #5 | 30M, 15M |       | 40 mm | 88mm  |
| EL2818A12N | 28 mm, 18 mm |        |          |       | 40 mm | 93mm  |
| EL3016A12N | 30 mm, 16 mm |        |          |       | 40 mm | 99mm  |
| EL2825A12N | 28 mm, 25 mm | #9, #8 | 30M, 25M |       | 40 mm | 104mm |
| EL3028A12N | 30 mm, 28 mm |        |          |       | 40 mm | 117mm |
| EL2820A12N | 28 mm, 20 mm | #9, #6 | 30M, 20M |       | 40 mm | 101mm |
| EL2822A12N | 28 mm, 22 mm | #9, #7 |          |       | 40 mm | 103mm |
| EL3018A12N | 30 mm, 18 mm |        |          |       | 40 mm | 103mm |
| EL3025A12N | 30 mm, 25 mm |        |          |       | 40 mm | 115mm |

|            |              |          |  |  |       |       |
|------------|--------------|----------|--|--|-------|-------|
| EL3020A12N | 30 mm, 20 mm |          |  |  | 40 mm | 110mm |
| EL3022A12N | 30 mm, 22 mm |          |  |  | 40 mm | 113mm |
| EL3216A12N | 32 mm, 16 mm | #10, #5  |  |  | 45 mm | 92mm  |
| EL3218A12N | 32 mm, 18 mm |          |  |  | 45 mm | 98mm  |
| EL3228A12N | 32 mm, 28 mm | #10, #9  |  |  | 45 mm | 110mm |
| EL4038A12N | 40 mm, 38 mm |          |  |  | 55 mm | 133mm |
| EL3432A12N | 34 mm, 32 mm |          |  |  | 50 mm | 123mm |
| EL3632A12N | 36 mm, 32 mm | #11, #10 |  |  | 50 mm | 120mm |
| EL3836A12N | 38 mm, 36 mm | #12, #11 |  |  | 55 mm | 128mm |
| EL3634A12N | 36 mm, 34 mm |          |  |  | 50 mm | 130mm |
| EL4036A12N | 40 mm, 36 mm |          |  |  | 55 mm | 132mm |
| EL3225A12N | 32 mm, 25 mm | #10, #8  |  |  | 45 mm | 109mm |
| EL3230A12N | 32 mm, 30 mm |          |  |  | 45 mm | 120mm |
| EL3428A12N | 34 mm, 28 mm |          |  |  | 50 mm | 120mm |
| EL3832A12N | 38 mm, 32 mm |          |  |  | 55 mm | 122mm |
| EL3220A12N | 32 mm, 20 mm | #10, #6  |  |  | 45 mm | 105mm |
| EL3430A12N | 34 mm, 30 mm |          |  |  | 50 mm | 131mm |
| EL3834A12N | 38 mm, 34 mm |          |  |  | 55 mm | 132mm |
| EL4032A12N | 40 mm, 32 mm |          |  |  | 55 mm | 126mm |

|             |              |          |          |  |       |       |
|-------------|--------------|----------|----------|--|-------|-------|
| EL4034A12N  | 40 mm, 34 mm |          |          |  | 55 mm | 136mm |
| EL3222A12N  | 32 mm, 22 mm | #10, #7  |          |  | 45 mm | 107mm |
| EL3628A12N  | 36 mm, 28 mm | #11, #9  | 35M, 30M |  | 50 mm | 118mm |
| EL3630A12N  | 36 mm, 30 mm |          |          |  | 50 mm | 128mm |
| EL3425A12N  | 34 mm, 25 mm |          |          |  | 50 mm | 119mm |
| EL3828A12N  | 38 mm, 28 mm | #12, #9  |          |  | 55 mm | 119mm |
| EL3625A12N  | 36 mm, 25 mm | #11, #8  | 35M, 25M |  | 50 mm | 116mm |
| EL3830A12N  | 38 mm, 30 mm |          |          |  | 55 mm | 130mm |
| EL4028A12N  | 40 mm, 28 mm |          |          |  | 55 mm | 123mm |
| EL4030A12N  | 40 mm, 30 mm |          |          |  | 55 mm | 134mm |
| EL3422A12N  | 34 mm, 22 mm |          |          |  | 50 mm | 117mm |
| EL3825A12N  | 38 mm, 25 mm | #12, #8  |          |  | 55 mm | 118mm |
| EL4025A12N  | 40 mm, 25 mm |          |          |  | 55 mm | 122mm |
| EL3420A12N  | 34 mm, 20 mm |          |          |  | 50 mm | 115mm |
| EL3622A12N  | 36 mm, 22 mm | #11, #7  |          |  | 50 mm | 114mm |
| EL3620A12N  | 36 mm, 20 mm | #11, #6  | 35M, 20M |  | 50 mm | 112mm |
| EL43T36A12N | 43 mm, 36 mm | #14, #11 | 45M, 35M |  | 60 mm | 148mm |
| EL50T40A12N | 50 mm, 40 mm |          |          |  | 70 mm | 157mm |
| EL50T38A12N | 50 mm, 38 mm |          |          |  | 70 mm | 154mm |

|              |              |          |          |  |       |       |
|--------------|--------------|----------|----------|--|-------|-------|
| EL50T36A12N  | 50 mm, 36 mm |          |          |  | 70 mm | 153mm |
| EL50T32A12N  | 50 mm, 32 mm |          |          |  | 70 mm | 147mm |
| EL50T34A12N  | 50 mm, 34 mm |          |          |  | 70 mm | 156mm |
| EL57T43TA12N | 57 mm, 43 mm | #18, #14 | 55M, 45M |  | 80 mm | 184mm |

Table 2/2

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand (BG) | Stückgewicht | Zertifizierungen                                                                                                        |
|---------------|----------------------|----------------------|------------------|--------------|-------------------------------------------------------------------------------------------------------------------------|
| EL1210A12N    | 19mm                 | 18mm                 | 18mm             | 0.08 kg      | DIBt, RISE, nVent LENTON EPD - Product Specific, Kontrollrådet, ITB                                                     |
| EL1412A12N    | 21mm                 | 19mm                 | 17mm             | 0.14 kg      | KOMO, nVent LENTON EPD - Product Specific, CARES, Kontrollrådet, Kontrollrådet, ITB, DIBt, RISE                         |
| EL1612A12N    | 24mm                 | 19mm                 | 18mm             | 0.14 kg      | LA City Approval, RISE, CARES, IAPMO®-UES, KOMO, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet, ITB |
| EL1614A12N    | 24mm                 | 21mm                 | 19mm             | 0.14 kg      | DIBt, RISE, KOMO, nVent LENTON EPD - Product Specific, CARES, Kontrollrådet, Kontrollrådet, ITB                         |
| EL1410A12N    | 21mm                 | 18mm                 | 18mm             | 0.15 kg      | nVent LENTON EPD - Product Specific, Kontrollrådet, ITB                                                                 |
| EL1610A12N    | 24mm                 | 18mm                 | 19mm             | 0.15 kg      | nVent LENTON EPD - Product Specific, Kontrollrådet, ITB                                                                 |

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand (BG) | Stückgewicht | Zertifizierungen                                                                                                              |
|---------------|----------------------|----------------------|------------------|--------------|-------------------------------------------------------------------------------------------------------------------------------|
| EL1810A12N    | 29mm                 | 18mm                 | 19mm             | 0.25 kg      | nVent LENTON EPD - Product Specific, ITB                                                                                      |
| EL1812A12N    | 29mm                 | 19mm                 | 18mm             | 0.25 kg      | nVent LENTON EPD - Product Specific, ITB                                                                                      |
| EL1814A12N    | 29mm                 | 21mm                 | 19mm             | 0.25 kg      | nVent LENTON EPD - Product Specific, ITB                                                                                      |
| EL1816A12N    | 29mm                 | 24mm                 | 18mm             | 0.25 kg      | nVent LENTON EPD - Product Specific, ITB                                                                                      |
| EL2012A12N    | 35mm                 | 19mm                 | 20mm             | 0.26 kg      | CARES, KOMO, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet, ITB, RISE                                     |
| EL2010A12N    | 35mm                 | 18mm                 | 21mm             | 0.27 kg      | ITB, nVent LENTON EPD - Product Specific, Kontrollrådet                                                                       |
| EL2014A12N    | 35mm                 | 21mm                 | 21mm             | 0.27 kg      | ITB, RISE, KOMO, nVent LENTON EPD - Product Specific, CARES, Kontrollrådet, Kontrollrådet                                     |
| EL2016A12N    | 35mm                 | 24mm                 | 21mm             | 0.27 kg      | ITB, LA City Approval, DIBt, RISE, CARES, IAPMO®-UES, KOMO, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet |
| EL2018A12N    | 35mm                 | 29mm                 | 21mm             | 0.27 kg      | nVent LENTON EPD - Product Specific, ITB                                                                                      |
| EL2212A12N    | 37mm                 | 19mm                 | 21mm             | 0.34 kg      | nVent LENTON EPD - Product Specific, ITB                                                                                      |

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand (BG) | Stückgewicht | Zertifizierungen                                                                          |
|---------------|----------------------|----------------------|------------------|--------------|-------------------------------------------------------------------------------------------|
| EL2210A12N    | 37mm                 | 18mm                 | 22mm             | 0.35 kg      | ITB, nVent LENTON EPD - Product Specific                                                  |
| EL2214A12N    | 37mm                 | 21mm                 | 22mm             | 0.35 kg      | ITB, nVent LENTON EPD - Product Specific                                                  |
| EL2216A12N    | 37mm                 | 24mm                 | 22mm             | 0.35 kg      | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL2218A12N    | 37mm                 | 29mm                 | 21mm             | 0.36 kg      | ITB, nVent LENTON EPD - Product Specific                                                  |
| EL2220A12N    | 37mm                 | 35mm                 | 23mm             | 0.38 kg      | ITB, LA City Approval, IAPMO®-UES, nVent LENTON EPD - Product Specific                    |
| EL2512A12N    | 40mm                 | 19mm                 | 22mm             | 0.43 kg      | CARES, KOMO, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet, ITB, RISE |
| EL2510A12N    | 40mm                 | 18mm                 | 23mm             | 0.44 kg      | nVent LENTON EPD - Product Specific, Kontrollrådet                                        |
| EL2514A12N    | 40mm                 | 21mm                 | 22mm             | 0.44 kg      | ITB, RISE, KOMO, nVent LENTON EPD - Product Specific, CARES, Kontrollrådet, Kontrollrådet |
| EL2516A12N    | 40mm                 | 24mm                 | 22mm             | 0.45 kg      | CARES, KOMO, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet, ITB, RISE |
| EL2518A12N    | 40mm                 | 29mm                 | 21mm             | 0.47 kg      | ITB, nVent LENTON EPD - Product Specific                                                  |

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand (BG) | Stückgewicht | Zertifizierungen                                                                                |
|---------------|----------------------|----------------------|------------------|--------------|-------------------------------------------------------------------------------------------------|
| EL2522A12N    | 40mm                 | 37mm                 | 23mm             | 0.49 kg      | ITB, LA City Approval, IAPMO®-UES, nVent LENTON EPD - Product Specific                          |
| EL2520A12N    | 40mm                 | 35mm                 | 23mm             | 0.5 kg       | CARES, KOMO, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet, ITB, DIBt, RISE |
| EL2814A12N    | 42mm                 | 21mm                 | 23mm             | 0.61 kg      | ITB, KOMO, nVent LENTON EPD - Product Specific                                                  |
| EL2816A12N    | 42mm                 | 24mm                 | 22mm             | 0.62 kg      | KOMO, nVent LENTON EPD - Product Specific, ITB                                                  |
| EL2818A12N    | 42mm                 | 29mm                 | 22mm             | 0.65 kg      | ITB, nVent LENTON EPD - Product Specific                                                        |
| EL3016A12N    | 52mm                 | 24mm                 | 23mm             | 0.66 kg      | nVent LENTON EPD - Product Specific                                                             |
| EL2825A12N    | 42mm                 | 40mm                 | 22mm             | 0.67 kg      | ITB, LA City Approval, DIBt, IAPMO®-UES, KOMO, nVent LENTON EPD - Product Specific              |
| EL3028A12N    | 52mm                 | 42mm                 | 23mm             | 0.68 kg      | nVent LENTON EPD - Product Specific                                                             |
| EL2820A12N    | 42mm                 | 35mm                 | 24mm             | 0.69 kg      | KOMO, nVent LENTON EPD - Product Specific, ITB                                                  |
| EL2822A12N    | 42mm                 | 37mm                 | 24mm             | 0.69 kg      | ITB, nVent LENTON EPD - Product Specific                                                        |
| EL3018A12N    | 52mm                 | 29mm                 | 22mm             | 0.69 kg      | nVent LENTON EPD - Product Specific                                                             |

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand (BG) | Stückgewicht | Zertifizierungen                                                                          |
|---------------|----------------------|----------------------|------------------|--------------|-------------------------------------------------------------------------------------------|
| EL3025A12N    | 52mm                 | 40mm                 | 23mm             | 0.71 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL3020A12N    | 52mm                 | 35mm                 | 23mm             | 0.73 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL3022A12N    | 52mm                 | 37mm                 | 24mm             | 0.73 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL3216A12N    | 45mm                 | 24mm                 | 23mm             | 0.81 kg      | ITB, RISE, CARES, KOMO, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet |
| EL3218A12N    | 45mm                 | 29mm                 | 24mm             | 0.86 kg      | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL3228A12N    | 45mm                 | 42mm                 | 23mm             | 0.88 kg      | IAPMO®-UES, KOMO, nVent LENTON EPD - Product Specific, ITB, LA City Approval, DIBt        |
| EL4038A12N    | 57mm                 | 53mm                 | 23mm             | 1.47 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL3432A12N    | 55mm                 | 45mm                 | 23mm             | 1.24 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL3632A12N    | 52mm                 | 45mm                 | 23mm             | 1.15 kg      | LA City Approval, IAPMO®-UES, nVent LENTON EPD - Product Specific                         |
| EL3836A12N    | 53mm                 | 52mm                 | 23mm             | 1.51 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL3634A12N    | 52mm                 | 55mm                 | 23mm             | 1.23 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL4036A12N    | 57mm                 | 52mm                 | 23mm             | 1.5 kg       | nVent LENTON EPD - Product Specific                                                       |

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand (BG) | Stückgewicht | Zertifizierungen                                                                          |
|---------------|----------------------|----------------------|------------------|--------------|-------------------------------------------------------------------------------------------|
| EL3225A12N    | 45mm                 | 40mm                 | 24mm             | 0.91 kg      | ITB, RISE, CARES, KOMO, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet |
| EL3230A12N    | 45mm                 | 52mm                 | 23mm             | 0.95 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL3428A12N    | 55mm                 | 42mm                 | 23mm             | 1.28 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL3832A12N    | 53mm                 | 45mm                 | 24mm             | 1.51 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL3220A12N    | 45mm                 | 35mm                 | 25mm             | 0.92 kg      | ITB, RISE, CARES, KOMO, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet |
| EL3430A12N    | 55mm                 | 52mm                 | 24mm             | 1.37 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL3834A12N    | 53mm                 | 55mm                 | 24mm             | 1.62 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL4032A12N    | 57mm                 | 45mm                 | 24mm             | 1.5 kg       | CARES, nVent LENTON EPD - Product Specific, Kontrollrådet, ITB, DIBt, RISE                |
| EL4034A12N    | 57mm                 | 55mm                 | 24mm             | 1.61 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL3222A12N    | 45mm                 | 37mm                 | 25mm             | 0.93 kg      | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL3628A12N    | 52mm                 | 42mm                 | 24mm             | 1.19 kg      | nVent LENTON EPD - Product Specific                                                       |
| EL3630A12N    | 52mm                 | 52mm                 | 24mm             | 1.28 kg      | nVent LENTON EPD - Product Specific                                                       |


| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand (BG) | Stückgewicht | Zertifizierungen                                                     |
|---------------|----------------------|----------------------|------------------|--------------|----------------------------------------------------------------------|
| EL3425A12N    | 55mm                 | 40mm                 | 24mm             | 1.31 kg      | nVent LENTON EPD - Product Specific                                  |
| EL3828A12N    | 53mm                 | 42mm                 | 24mm             | 1.54 kg      | nVent LENTON EPD - Product Specific                                  |
| EL3625A12N    | 52mm                 | 40mm                 | 24mm             | 1.22 kg      | nVent LENTON EPD - Product Specific                                  |
| EL3830A12N    | 53mm                 | 52mm                 | 25mm             | 1.67 kg      | nVent LENTON EPD - Product Specific                                  |
| EL4028A12N    | 57mm                 | 42mm                 | 24mm             | 1.54 kg      | nVent LENTON EPD - Product Specific, ITB                             |
| EL4030A12N    | 57mm                 | 52mm                 | 25mm             | 1.66 kg      | nVent LENTON EPD - Product Specific                                  |
| EL3422A12N    | 55mm                 | 37mm                 | 25mm             | 1.32 kg      | nVent LENTON EPD - Product Specific                                  |
| EL3825A12N    | 53mm                 | 40mm                 | 25mm             | 1.56 kg      | nVent LENTON EPD - Product Specific                                  |
| EL4025A12N    | 57mm                 | 40mm                 | 25mm             | 1.56 kg      | CARES, nVent LENTON EPD - Product Specific, Kontrollrådet, ITB, RISE |
| EL3420A12N    | 55mm                 | 35mm                 | 25mm             | 1.31 kg      | nVent LENTON EPD - Product Specific                                  |
| EL3622A12N    | 52mm                 | 37mm                 | 25mm             | 1.22 kg      | nVent LENTON EPD - Product Specific                                  |
| EL3620A12N    | 52mm                 | 35mm                 | 25mm             | 1.22 kg      | nVent LENTON EPD - Product Specific                                  |
| EL43T36A12N   | 66mm                 | 52mm                 | 30mm             | 2.1 kg       | LA City Approval, IAPMO®-UES, nVent LENTON EPD - Product Specific    |

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand (BG) | Stückgewicht | Zertifizierungen                                                  |
|---------------|----------------------|----------------------|------------------|--------------|-------------------------------------------------------------------|
| EL50T40A12N   | 70mm                 | 57mm                 | 30mm             | 3.09 kg      | CARES, nVent LENTON EPD - Product Specific                        |
| EL50T38A12N   | 70mm                 | 53mm                 | 31mm             | 3.06 kg      | nVent LENTON EPD - Product Specific                               |
| EL50T36A12N   | 70mm                 | 52mm                 | 31mm             | 3.08 kg      | nVent LENTON EPD - Product Specific                               |
| EL50T32A12N   | 70mm                 | 45mm                 | 32mm             | 3 kg         | CARES, nVent LENTON EPD - Product Specific                        |
| EL50T34A12N   | 70mm                 | 55mm                 | 31mm             | 3.22 kg      | nVent LENTON EPD - Product Specific                               |
| EL57T43TA12N  | 83mm                 | 66mm                 | 35mm             | 4.87 kg      | LA City Approval, IAPMO®-UES, nVent LENTON EPD - Product Specific |

## ZUSÄTZLICHE PRODUKTDDETAILS

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMME

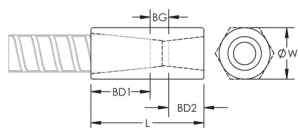

## WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter [www.nVent.com](http://www.nVent.com) sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.

#### **Nordamerika**

+1.800.753.9221

Option 1 – Kundendienst

Option 2 – Technischer

Support

#### **Europa**

Niederlande:

+31 800-0200135

Frankreich:

+33 800 901 793

#### **Europa**

Deutschland:

800 1890272

Sonstige Länder:

+31 13 5835404

#### **APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Unser starkes markenportfolio:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**