


EuropacPRO 19" Subrack Kit for Power Distribution Module, Unshielded

Energieversorger

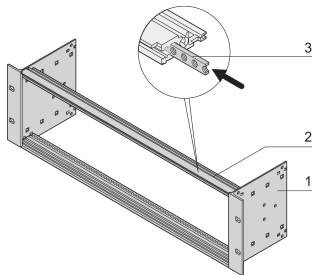

For mounting installation devices in accordance with DIN 43880 in sizes 1-3 with snap-in technology e.g. mounting sockets, circuit breakers or residual current circuit breaker. These can be fitted after the horizontal rail with lip DIN central rail (35/7.5) are fitted.

ZERTIFIZIERUNGEN



EIGENSCHAFTEN

For mounting installation devices in accordance with DIN 43880 in sizes 1-3 with snap-in technology e.g. mounting sockets, circuit breakers or residual current circuit breaker. These can be fitted after the horizontal rail with lip DIN central rail (35/7.5) are fitted

Modular frame to accept e.g. power distribution modules

Internal and external dimensions in accordance with the IEC 60297-3-101 and IEEE 1101.1 standards

Aluminium side panels

Horizontal rails type "light"

IEEE 1101.1 compatible

SPEZIFIKATIONEN

Table 1/2

Katalognummer	Product Type	Rack Height	Rack Width	Tiefe	For Mounting	EMC Shielding
---------------	--------------	-------------	------------	-------	--------------	---------------

24563-100	Subrack/Chassis	3 U	84 HP	115 mm	Power Distribution Module	Nein
-----------	-----------------	-----	-------	--------	---------------------------	------

Table 2/2

Katalognummer	Statische Last	Handle Included	Montage	Konform mit	Package Quantity
24563-100	2.5 kgf	Nein	Rack	IEC 60297-3-103	1

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE