


RatiopacPRO AIR 19" Rack Mount Case, Retrofittable Shielding With Handles

Energieversorger

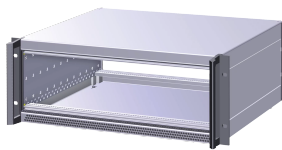

The nVent SCHROFF RatiopacPRO case provides electronics protection for 19" and individual electronic assemblies. This flexible and robust case is simple to convert from desktop to a 19" rack mount case and includes four different style options. This version of the case provides advanced cooling capabilities and mounting brackets with handles for assembly into a 19" rack.

ZERTIFIZIERUNGEN



EIGENSCHAFTEN

Cases for individual assembly with 19" standard components or specific internal mounting, e.g. with mounting plate

Retrofittable EMC shielding

Version with 19" mounting brackets with front handles, no visible screws

The case has 2 x 1/2 U clearances for ventilation beneath and above the board cage

For board depth 160 mm, 220 mm, 280 mm, and 340 mm (depending on case depth)

Symmetrical design, identical front and rear side

Conforms with DIN EN 62368-1

SPEZIFIKATIONEN

Table 1/3

Katalognummer	Rack Height	Tiefe	Package Quantity	Usable Height	Usable Width	Front Frame Construction
---------------	-------------	-------	------------------	---------------	--------------	--------------------------

24572-670	3 U	255.5 mm	1	112.3 mm	432 mm	19" Mounting Brackets with Handles, Horizontal Rails
24572-673	3 U	315.5 mm	1	112.3 mm	432 mm	19" Mounting Brackets with Handles, Horizontal Rails
24572-674	3 U	375.5 mm	1	112.3 mm	432 mm	19" Mounting Brackets with Handles, Horizontal Rails
24572-675	3 U	435.5 mm	1	112.3 mm	432 mm	19" Mounting Brackets with Handles, Horizontal Rails
24572-676	3 U	495.5 mm	1	112.3 mm	432 mm	19" Mounting Brackets with Handles, Horizontal Rails
24572-690	6 U	255.5 mm	1	245.7 mm	432 mm	19" Mounting Brackets with Handles, Horizontal Rails
24572-693	6 U	315.5 mm	1	245.7 mm	432 mm	19" Mounting Brackets with Handles, Horizontal Rails
24572-694	6 U	375.5 mm	1	245.7 mm	432 mm	19" Mounting Brackets with Handles, Horizontal Rails
24572-695	6 U	435.5 mm	1	245.7 mm	432 mm	19" Mounting Brackets with Handles, Horizontal Rails
24572-696	6 U	495.5 mm	1	245.7 mm	432 mm	19" Mounting Brackets with Handles, Horizontal Rails

Table 2/3

Katalognummer	Cooling Option	Konform mit	EMC Shielding	Höhe	Product Family	Product Type
---------------	----------------	-------------	---------------	------	----------------	--------------

24572-670	Ja	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11	No (Retrofittable)	177 mm	RatiopacPRO AIR	Gehäuse
24572-673	Ja	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11	No (Retrofittable)	177 mm	RatiopacPRO AIR	Gehäuse
24572-674	Ja	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11	No (Retrofittable)	177 mm	RatiopacPRO AIR	Gehäuse
24572-675	Ja	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11	No (Retrofittable)	177 mm	RatiopacPRO AIR	Gehäuse
24572-676	Ja	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11	No (Retrofittable)	177 mm	RatiopacPRO AIR	Gehäuse
24572-690	Ja	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11	No (Retrofittable)	310.35 mm	RatiopacPRO AIR	Gehäuse
24572-693	Ja	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11	No (Retrofittable)	310.35 mm	RatiopacPRO AIR	Gehäuse
24572-694	Ja	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11	No (Retrofittable)	310.35 mm	RatiopacPRO AIR	Gehäuse

24572-695	Ja	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11	No (Retrofittable)	310.35 mm	RatiopacPRO AIR	Gehäuse
24572-696	Ja	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11	No (Retrofittable)	310.35 mm	RatiopacPRO AIR	Gehäuse

Table 3/3

Katalognummer	Protection Rating	Rack Width	Statische Last	Typ	Breite
24572-670	IP20	84 HP	25 kgf	Case for Individual Electronic Components	448.9 mm
24572-673	IP20	84 HP	25 kgf	Case for Individual Electronic Components	448.9 mm
24572-674	IP20	84 HP	25 kgf	Case for Individual Electronic Components	448.9 mm
24572-675	IP20	84 HP	25 kgf	Case for Individual Electronic Components	448.9 mm
24572-676	IP20	84 HP	25 kgf	Case for Individual Electronic Components	448.9 mm
24572-690	IP20	84 HP	25 kgf	Case for Individual Electronic Components	448.9 mm
24572-693	IP20	84 HP	25 kgf	Case for Individual Electronic Components	448.9 mm
24572-694	IP20	84 HP	25 kgf	Case for Individual Electronic Components	448.9 mm
24572-695	IP20	84 HP	25 kgf	Case for Individual Electronic Components	448.9 mm
24572-696	IP20	84 HP	25 kgf	Case for Individual Electronic Components	448.9 mm

ADDITIONAL PRODUCT DETAILS

Modifications (special colours or sizes).

Custom solutions (cut-outs in top cover, base plate or side panels).

Assembly service from 1 piece.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE