

# T-Series Vertical Transition Splice Kit



T-Series splice kits contain the following: Sleeve, filler material kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), pouring basin and pouring basin crucible. Splice kits are ordered based on the quantity of splices needed. Sleeves and filler material kits are one-time use parts. Pouring basins and crucibles are prorated based on their anticipated life. Ordering splice kits simplifies ordering, reduces order errors and helps ensure proper sizing of components. Kits can be ordered with longer (extended) sleeves for use when the reinforcing steel deformation pattern or spacing does not meet the minimum product specifications.

## MERKMALE

Simplifies ordering

Used to splice different diameter bars

## SPEZIFIKATIONEN

**Hülse:** Standardlänge

Table 1/2

| Katalognummer | Bewehrungsstabgröße, metrisch | Größe Armierung, USA | Größe Armierung, Kanada | Länge 1 (L1) | Länge 2 (L2) | Höhe 1 (H1) |
|---------------|-------------------------------|----------------------|-------------------------|--------------|--------------|-------------|
| RBT67101      | 22 mm, 20 mm                  | #7, #6               |                         | 356 mm       | 51 mm        | 654mm       |
| RBT710101     | 32 mm, 22 mm                  | #10, #7              |                         | 362 mm       | 51 mm        | 660mm       |
| RBT78101      | 25 mm, 22 mm                  | #8, #7               |                         | 356 mm       | 51 mm        | 654mm       |
| RBT79101      | 28 mm, 22 mm                  | #9, #7               |                         | 362 mm       | 51 mm        | 654mm       |
| RBT810101     | 32 mm, 25 mm                  | #10, #8              |                         | 362 mm       | 51 mm        | 660mm       |
| RBT89101      | 28 mm, 25 mm                  | #9, #8               | 30M, 25M                | 362 mm       | 51 mm        | 654mm       |

| Katalognummer | Bewehrungssta<br>bgröße,<br>metrisch | Größe<br>Armierung,USA | Größe<br>Armierung,<br>Kanada | Länge 1 (L1) | Länge 2 (L2) | Höhe 1 (H1) |
|---------------|--------------------------------------|------------------------|-------------------------------|--------------|--------------|-------------|
| RBT910101     | 32 mm, 28 mm                         | #10, #9                |                               | 362 mm       | 51 mm        | 660mm       |
| RBT1011101    | 36 mm, 32 mm                         | #11, #10               |                               | 375 mm       | 64 mm        | 713mm       |
| RBT1014101    | 43 mm, 32 mm                         | #14, #10               |                               | 387 mm       | 64 mm        | 725mm       |
| RBT1114101    | 43 mm, 36 mm                         | #14, #11               | 45M, 35M                      | 387 mm       | 64 mm        | 725mm       |
| RBT1118101    | 57 mm, 36 mm                         | #18, #11               | 55M, 35M                      | 394 mm       | 64 mm        | 806mm       |
| RBT1418101    | 57 mm, 43 mm                         | #18, #14               | 55M, 45M                      | 394 mm       | 64 mm        | 780mm       |
| RBT711101     | 36 mm, 22 mm                         | #11, #7                |                               | 375 mm       | 64 mm        | 686mm       |
| RBT811101     | 36 mm, 25 mm                         | #11, #8                | 35M, 25M                      | 375 mm       | 64 mm        | 686mm       |
| RBT911101     | 36 mm, 28 mm                         | #11, #9                | 35M, 30M                      | 375 mm       | 64 mm        | 713mm       |
| RBT914101     | 43 mm, 28 mm                         | #14, #9                | 45M, 30M                      | 387 mm       | 64 mm        | 725mm       |

| Table 2/2     |             |             |             |                 |
|---------------|-------------|-------------|-------------|-----------------|
| Katalognummer | Höhe 2 (H2) | Höhe 3 (H3) | Höhe 4 (H4) | Durchmesser (Ø) |
| RBT67101      | 451mm       | 203mm       | 197mm       | 102 mm          |
| RBT710101     | 451mm       | 210mm       | 197mm       | 127 mm          |
| RBT78101      | 451mm       | 203mm       | 197mm       | 102 mm          |
| RBT79101      | 451mm       | 203mm       | 197mm       | 127 mm          |
| RBT810101     | 451mm       | 210mm       | 197mm       | 127 mm          |
| RBT89101      | 451mm       | 203mm       | 197mm       | 127 mm          |

| Katalognummer | Höhe 2 (H2) | Höhe 3 (H3) | Höhe 4 (H4) | Durchmesser (Ø) |
|---------------|-------------|-------------|-------------|-----------------|
| RBT910101     | 451mm       | 210mm       | 197mm       | 127 mm          |
| RBT1011101    | 497mm       | 216mm       | 210mm       | 152 mm          |
| RBT1014101    | 497mm       | 229mm       | 222mm       | 152 mm          |
| RBT1114101    | 297mm       | 229mm       | 222mm       | 152 mm          |
| RBT1118101    | 552mm       | 254mm       | 216mm       | 178 mm          |
| RBT1418101    | 526mm       | 254mm       | 216mm       | 152 mm          |
| RBT711101     | 216mm       | 216mm       | 210mm       | 127 mm          |
| RBT811101     | 216mm       | 216mm       | 210mm       | 127 mm          |
| RBT911101     | 497mm       | 216mm       | 210mm       | 152 mm          |
| RBT914101     | 497mm       | 229mm       | 222mm       | 152 mm          |

## ZUSÄTZLICHE PRODUKTDDETAILS


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

All dimensions are for reference only.

Components can also be purchased separately: (1) Sleeve, (2) Filler Material Kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), (3) Pouring Basin, and (4) Pouring Basin Crucible.

| Splice Kit Components |                 |                         |                                       |                                  |             |               |                        |
|-----------------------|-----------------|-------------------------|---------------------------------------|----------------------------------|-------------|---------------|------------------------|
| Splice Kit            | Filler Material | Packing (2 Required)    | Pouring Basin Ceramic Insert and Disk | Pouring Basin Ceramic Guide Tube | Sleeve      | Pouring Basin | Pouring Basin Crucible |
| RBT67101              | RBF55           | RBS35473.5<br>RBS35478  | RBS5037                               | RBS5038                          | RBT7101A    | RBWS1500A     | RBWS22774              |
| RBT78101              | RBF70           | RBS354710<br>RBS35475   | RBS5037                               | RBS5038                          | RBT8101A    | RBWS1500C     | RBWS22774              |
| RBT79101              | RBF90           | RBS35475<br>RBS35478    | RBS5037                               | RBS5038                          | RBT9101A    | RBWS1500D     | RBWS22775              |
| RBT89101              | RBF90           | RBS354711<br>RBS35475.5 | RBS5037                               | RBS5038                          | RBT9101A    | RBWS1500D     | RBWS22775              |
| RBT710101             | RBF105          | RBS354710<br>RBS35477   | RBS5037                               | RBS5038                          | RBT1091A    | RBWS1500E     | RBWS22775              |
| RBT810101             | RBF105          | RBS354710<br>RBS354712  | RBS5037                               | RBS5038                          | RBT1091A    | RBWS1500E     | RBWS22775              |
| RBT910101             | RBF105          | RBS354712<br>RBS35475.5 | RBS5037                               | RBS5038                          | RBT1091A    | RBWS1500E     | RBWS22775              |
| RBT711101             | RBF105          | RBS354714<br>RBS35477   | RBS5037                               | RBS5038                          | RBT11101A   | RBWS1499F     | RBWS22775              |
| RBT811101             | RBF105          | RBS354714<br>RBS35477   | RBS5037                               | RBS5038                          | RBT11101A   | RBWS1499F     | RBWS22775              |
| RBT911101             | RBF125          | RBS354714<br>RBS35476   | RBS5037                               | RBS5038                          | RBT11101A   | RBWS1499F     | RBWS22776              |
| RBT1011101            | RBF125          | RBS354712<br>RBS35476   | RBS5037                               | RBS5038                          | RBT11101A   | RBWS1499F     | RBWS22776              |
| RBT914101             | RBF150          | RBS354720<br>RBS35479   | RBS5037                               | RBS5039                          | RBT1114101A | RBWS1499G     | RBWS22776              |
| RBT1014101            | RBF125          | RBS354715<br>RBS35479   | RBS5037                               | RBS5039                          | RBT1114101A | RBWS1499G     | RBWS22776              |
| RBT1114101            | RBF125          | RBS354715<br>RBS35476   | RBS5037                               | RBS5039                          | RBT1114101A | RBWS1499G     | RBWS22776              |
| RBT1118101            | RBF240          | RBS354712<br>RBS354720  | RBS5037                               | RBS5039                          | RBT1418101A | RBWS1481K     | RBWS22777              |
| RBT1418101            | RBF195          | RBS354720<br>RBS35477   | RBS5037                               | RBS5039                          | RBT1418101A | RBWS1481K     | RBWS22776              |

## DIAGRAMME

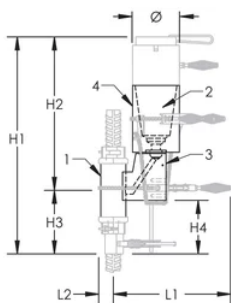

## WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter [www.nVent.com](http://www.nVent.com) sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.

### Nordamerika

+1.800.753.9221

Option 1 – Kundendienst

Option 2 – Technischer

Support

### Europa

Niederlande:

+31 800-0200135

Frankreich:

+33 800 901 793

### Europa

Deutschland:

800 1890272

Sonstige Länder:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Unser starkes markenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE