


EuropacPRO Cover Plate for Bolting to Rugged Side Panel, 84 HP, 235 mm

Energieversorger

KATALOGNUMMER

24568-008

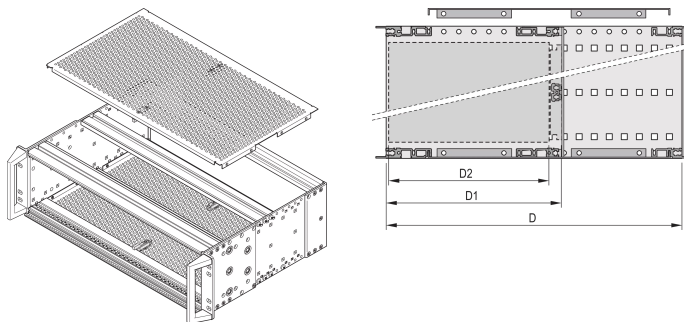

A cover plate is used for electromagnetic shielding or as mechanical protection.

ZERTIFIZIERUNGEN



EIGENSCHAFTEN

Perforation degree 58%

PRODUKTMERKMALE

Product Type: Deckplatte

Product Family: EuropacPRO

Type: Perforiert

Rack Width: 84 HP

Tiefe: 235 mm

Package Quantity: 1

Package Unit: Paar

Torque: 2,1 N·m

ADDITIONAL PRODUCT DETAILS

A top cover locking mechanism is optionally available that also fixes the top cover in the front and rear guide rail.

4 stainless steel EMC contact strips per subrack are required for shielding, please order separately.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE