


Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts

Energieversorger

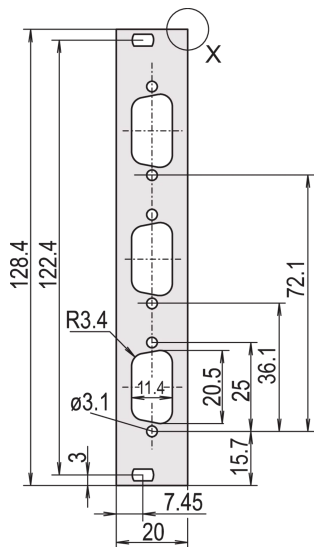

Flat front panel with cutout for D-Sub connectors.
Shieldable for stainless steel EMC gasket.

ZERTIFIZIERUNGEN



EIGENSCHAFTEN

For stainless steel EMC gasket

Aluminum, 2.5 mm, front anodized, conductive

SPEZIFIKATIONEN

Table 1/3

Katalognummer	Package Quantity	Montage	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
---------------	------------------	---------	-----------------	--------------	-------------	---------------

30118-348	5	Screw-on Front	Edelstahl	Anodized	Conductive	Nein
30118-349	5	Screw-on Front	Edelstahl	Anodized	Conductive	Nein
30118-350	5	Screw-on Front	Edelstahl	Anodized	Conductive	Nein
30118-351	5	Screw-on Front	Edelstahl	Anodized	Conductive	Nein
30118-352	5	Screw-on Front	Edelstahl	Anodized	Conductive	Nein
30118-353	5	Screw-on Front	Edelstahl	Anodized	Conductive	Nein
30118-354	5	Screw-on Front	Edelstahl	Anodized	Conductive	Nein

Table 2/3						
Katalognummer	Konform mit	EMC Shielding	Höhe	Material	Product Type	Rack Height
30118-348	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U
30118-349	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U
30118-350	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U
30118-351	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U
30118-352	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U
30118-353	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U
30118-354	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U

Table 3/3			
Katalognummer	Rack Width	Typ	Breite

30118-348	4 HP	Front Panel without Handle	20 mm
30118-349	4 HP	Front Panel without Handle	20 mm
30118-350	4 HP	Front Panel without Handle	20 mm
30118-351	4 HP	Front Panel without Handle	20 mm
30118-352	4 HP	Front Panel without Handle	20 mm
30118-353	4 HP	Front Panel without Handle	20 mm
30118-354	4 HP	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE