

Angular Pouring Basin, Side Fill, Variable Upper Component



Side fill pouring basins are used when interferences of the structure will not allow top filling of the sleeve. Variable angle side fill pouring basins are used when one of the predefined angle pouring basins is not available or when a project has multiple reinforcing steel angles.

The upper component is universal to all sleeve sizes and is always used in conjunction with the bottom component.

MERKMALE

Made from heat-resistant graphite

Durable, re-usable and long lasting

SPEZIFIKATIONEN

Table 1/2

Katalognummer	Material	Durchmesser (Ø)	Länge 1 (L1)	Länge 2 (L2)	Breite (W)	Höhe 1 (H1)
RBWS2468	Graphit	58 mm	159 mm	114 mm	76 mm	273mm

Table 2/2

Katalognummer	Höhe 2 (H2)	Anzahl Verpackungen
RBWS2468	102mm	1

ZUSÄTZLICHE PRODUKTDDETAILS


RBWS2468 pouring basins require one RBW350 and one RBW734 pouring basin frame and one RBS5000 bolt retainer (sold separately).

Contact nVent LENTON for assistance in sleeve selection.

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMME

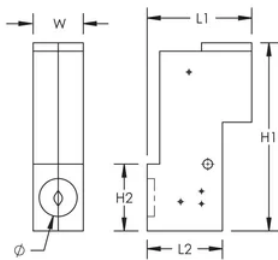

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.

Nordamerika

+1.800.753.9221

Option 1 – Kundendienst

Option 2 – Technischer

Support

Europa

Niederlande:

+31 800-0200135

Frankreich:

+33 800 901 793

Europa

Deutschland:

800 1890272

Sonstige Länder:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Unser starkes markenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE