

# Horizontal Pouring Basin, Top Fill, Standard



Standard horizontal pouring basins should be used whenever the clearances of the structure allow. The compact size of the standard pouring basins help ensure the best possible flow of filler material.

## MERKMALE

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal top fill sleeves

## SPEZIFIKATIONEN

**Material:** Graphit

Table 1/1

| Katalognummer | Durchmesser (Ø) | Länge (L) | Breite (W) | Höhe (H) |
|---------------|-----------------|-----------|------------|----------|
| RBWS1467D     | 54 mm           | 86mm      | 89 mm      | 102 mm   |
| RBWS1467F     | 64 mm           | 86mm      | 89 mm      | 102 mm   |
| RBWS1467M     | 95 mm           | 86mm      | 89 mm      | 102 mm   |
| RBWS1467U     | 35 mm           | 86mm      | 89 mm      | 102 mm   |
| RBWS1467X     | 38 mm           | 86mm      | 89 mm      | 102 mm   |
| RBWS1467E     | 57 mm           | 86mm      | 89 mm      | 102 mm   |

| Katalognummer | Durchmesser (Ø) | Länge (L) | Breite (W) | Höhe (H) |
|---------------|-----------------|-----------|------------|----------|
| RBWS1467G     | 70 mm           | 86mm      | 89 mm      | 102 mm   |
| RBWS1467C     | 48 mm           | 86mm      | 89 mm      | 102 mm   |
| RBWS1467A     | 41 mm           | 86mm      | 89 mm      | 102 mm   |
| RBWS1467K     | 86 mm           | 86mm      | 89 mm      | 102 mm   |
| RBWS1467H     | 73 mm           | 86mm      | 89 mm      | 102 mm   |
| RBWS1467J     | 76 mm           | 86mm      | 89 mm      | 102 mm   |


## ZUSÄTZLICHE PRODUKTDDETAILS

RBWS1467 pouring basins require one RBW167 pouring basin frame (sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMME

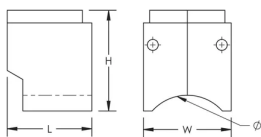

## WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter [www.nVent.com](http://www.nVent.com) sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.

#### **Nordamerika**

+1.800.753.9221

Option 1 – Kundendienst

Option 2 – Technischer

Support

#### **Europa**

Niederlande:

+31 800-0200135

Frankreich:

+33 800 901 793

#### **Europa**

Deutschland:

800 1890272

Sonstige Länder:

+31 13 5835404

#### **APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Unser starkes markenportfolio:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**