


# P14 Position Transition Coupler, Worldwide Design

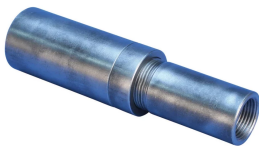

## ZERTIFIZIERUNGEN



## MERKMALE

Used to splice different diameter bars

Designed to splice two curved, bent or straight bars, when neither bar can be rotated and where the ongoing bar is free to move in its axial direction

## SPEZIFIKATIONEN

|                           |                                        |
|---------------------------|----------------------------------------|
| <b>Oberfläche:</b>        | Blank                                  |
| <b>Material:</b>          | Stahl                                  |
| <b>Auslegungsversion:</b> | Weltweit (global verfügbares Material) |

Table 1/2

| Katalognummer | Bewehrungsstabgröße, metrisch | Größe Armierung, USA | Größe Armierung, Kanada | Durchmesser (Ø) | Länge 1 (L1) | Länge 2 (L2) |
|---------------|-------------------------------|----------------------|-------------------------|-----------------|--------------|--------------|
| EL1210P14LN   | 12 mm, 10 mm                  | #4, #3               |                         | 25 mm           | 98 mm        | 105 mm       |

| Katalognummer | Bewehrungssta<br>bgröße,<br>metrisch | Größe<br>Armierung,USA | Größe<br>Armierung,<br>Kanada | Durchmesser<br>(Ø) | Länge 1 (L1) | Länge 2 (L2) |
|---------------|--------------------------------------|------------------------|-------------------------------|--------------------|--------------|--------------|
| EL1412P14LN   | 14 mm, 12 mm                         |                        |                               | 25 mm              | 105 mm       | 112 mm       |
| EL1410P14LN   | 14 mm, 10 mm                         |                        |                               | 25 mm              | 105 mm       | 112 mm       |
| EL1614P14LN   | 16 mm, 14 mm                         |                        |                               | 30 mm              | 113 mm       | 119 mm       |
| EL1612P14LN   | 16 mm, 12 mm                         | #5, #4                 | 15M, 10M                      | 30 mm              | 113 mm       | 119 mm       |
| EL1610P14LN   | 16 mm, 10 mm                         | #5, #3                 |                               | 30 mm              | 113 mm       | 119 mm       |
| EL1816P14LN   | 18 mm, 16 mm                         |                        |                               | 35 mm              | 125 mm       | 131 mm       |
| EL1814P14LN   | 18 mm, 14 mm                         |                        |                               | 35 mm              | 125 mm       | 131 mm       |
| EL1812P14LN   | 18 mm, 12 mm                         |                        |                               | 35 mm              | 125 mm       | 131 mm       |
| EL1810P14LN   | 18 mm, 10 mm                         |                        |                               | 35 mm              | 125 mm       | 131 mm       |
| EL2010P14LN   | 20 mm, 10 mm                         | #6, #3                 |                               | 35 mm              | 152 mm       | 163 mm       |
| EL2012P14LN   | 20 mm, 12 mm                         | #6, #4                 | 20M, 10M                      | 35 mm              | 152 mm       | 163 mm       |
| EL2212P14LN   | 22 mm, 12 mm                         | #7, #4                 |                               | 40 mm              | 160 mm       | 172 mm       |
| EL2512P14LN   | 25 mm, 12 mm                         | #8, #4                 | 25M, 10M                      | 45 mm              | 169 mm       | 180 mm       |
| EL2014P14LN   | 20 mm, 14 mm                         |                        |                               | 35 mm              | 152 mm       | 163 mm       |
| EL2214P14LN   | 22 mm, 14 mm                         |                        |                               | 40 mm              | 160 mm       | 172 mm       |
| EL2514P14LN   | 25 mm, 14 mm                         |                        |                               | 45 mm              | 169 mm       | 180 mm       |
| EL2814P14LN   | 28 mm, 14 mm                         |                        |                               | 50 mm              | 175 mm       | 187 mm       |
| EL2018P14LN   | 20 mm, 18 mm                         |                        |                               | 35 mm              | 152 mm       | 163 mm       |

| Katalognummer | Bewehrungssta<br>bgröße,<br>metrisch | Größe<br>Armierung,USA | Größe<br>Armierung,<br>Kanada | Durchmesser<br>(Ø) | Länge 1 (L1) | Länge 2 (L2) |
|---------------|--------------------------------------|------------------------|-------------------------------|--------------------|--------------|--------------|
| EL2016P14LN   | 20 mm, 16 mm                         | #6, #5                 | 20M, 15M                      | 35 mm              | 152 mm       | 163 mm       |
| EL2216P14LN   | 22 mm, 16 mm                         | #7, #5                 |                               | 40 mm              | 160 mm       | 172 mm       |
| EL2516P14LN   | 25 mm, 16 mm                         | #8, #5                 | 25M, 15M                      | 45 mm              | 169 mm       | 180 mm       |
| EL2816P14LN   | 28 mm, 16 mm                         | #9, #5                 | 30M, 15M                      | 50 mm              | 175 mm       | 187 mm       |
| EL3016P14LN   | 30 mm, 16 mm                         |                        |                               | 55 mm              | 198 mm       | 209 mm       |
| EL2218P14LN   | 22 mm, 18 mm                         |                        |                               | 40 mm              | 160 mm       | 172 mm       |
| EL2518P14LN   | 25 mm, 18 mm                         |                        |                               | 45 mm              | 169 mm       | 180 mm       |
| EL2818P14LN   | 28 mm, 18 mm                         |                        |                               | 50 mm              | 175 mm       | 187 mm       |
| EL3018P14LN   | 30 mm, 18 mm                         |                        |                               | 55 mm              | 198 mm       | 209 mm       |
| EL3218P14LN   | 32 mm, 18 mm                         |                        |                               | 60 mm              | 192 mm       | 203 mm       |
| EL2220P14LN   | 22 mm, 20 mm                         | #7, #6                 |                               | 40 mm              | 160 mm       | 172 mm       |
| EL2520P14LN   | 25 mm, 20 mm                         | #8, #6                 | 25M, 20M                      | 45 mm              | 169 mm       | 180 mm       |
| EL2820P14LN   | 28 mm, 20 mm                         | #9, #6                 | 30M, 20M                      | 50 mm              | 175 mm       | 187 mm       |
| EL3020P14LN   | 30 mm, 20 mm                         |                        |                               | 55 mm              | 198 mm       | 209 mm       |
| EL3220P14LN   | 32 mm, 20 mm                         | #10, #6                |                               | 60 mm              | 192 mm       | 203 mm       |
| EL3420P14LN   | 34 mm, 20 mm                         |                        |                               | 60 mm              | 213 mm       | 224 mm       |
| EL2522P14LN   | 25 mm, 22 mm                         | #8, #7                 |                               | 45 mm              | 169 mm       | 180 mm       |
| EL2822P14LN   | 28 mm, 22 mm                         | #9, #7                 |                               | 50 mm              | 175 mm       | 187 mm       |

| Katalognummer | Bewehrungssta<br>bgröße,<br>metrisch | Größe<br>Armierung,USA | Größe<br>Armierung,<br>Kanada | Durchmesser<br>(Ø) | Länge 1 (L1) | Länge 2 (L2) |
|---------------|--------------------------------------|------------------------|-------------------------------|--------------------|--------------|--------------|
| EL3022P14LN   | 30 mm, 22 mm                         |                        |                               | 55 mm              | 198 mm       | 209 mm       |
| EL3222P14LN   | 32 mm, 22 mm                         | #10, #7                |                               | 60 mm              | 192 mm       | 203 mm       |
| EL3422P14LN   | 34 mm, 22 mm                         |                        |                               | 60 mm              | 213 mm       | 224 mm       |
| EL3622P14LN   | 36 mm, 22 mm                         | #11, #7                |                               | 65 mm              | 207 mm       | 218 mm       |
| EL3225P14LN   | 32 mm, 25 mm                         | #10, #8                |                               | 60 mm              | 192 mm       | 203 mm       |
| EL3425P14LN   | 34 mm, 25 mm                         |                        |                               | 60 mm              | 213 mm       | 224 mm       |
| EL3625P14LN   | 36 mm, 25 mm                         | #11, #8                | 35M, 25M                      | 65 mm              | 207 mm       | 218 mm       |
| EL3825P14LN   | 38 mm, 25 mm                         | #12, #8                |                               | 70 mm              | 212 mm       | 223 mm       |
| EL2825P14LN   | 28 mm, 25 mm                         | #9, #8                 | 30M, 25M                      | 50 mm              | 175 mm       | 187 mm       |
| EL3025P14LN   | 30 mm, 25 mm                         |                        |                               | 55 mm              | 198 mm       | 209 mm       |
| EL3028P14LN   | 30 mm, 28 mm                         |                        |                               | 55 mm              | 198 mm       | 209 mm       |
| EL4028P14LN   | 40 mm, 28 mm                         |                        |                               | 70 mm              | 221 mm       | 232 mm       |
| EL3228P14LN   | 32 mm, 28 mm                         | #10, #9                |                               | 60 mm              | 192 mm       | 203 mm       |
| EL3428P14LN   | 34 mm, 28 mm                         |                        |                               | 60 mm              | 213 mm       | 224 mm       |
| EL3628P14LN   | 36 mm, 28 mm                         | #11, #9                | 35M, 30M                      | 65 mm              | 207 mm       | 218 mm       |
| EL3828P14LN   | 38 mm, 28 mm                         | #12, #9                |                               | 70 mm              | 212 mm       | 223 mm       |
| EL3230P14LN   | 32 mm, 30 mm                         |                        |                               | 60 mm              | 192 mm       | 203 mm       |
| EL3432P14LN   | 34 mm, 32 mm                         |                        |                               | 60 mm              | 213 mm       | 224 mm       |

| Katalognummer | Bewehrungssta<br>bgröße,<br>metrisch | Größe<br>Armierung,USA | Größe<br>Armierung,<br>Kanada | Durchmesser<br>(Ø) | Länge 1 (L1) | Länge 2 (L2) |
|---------------|--------------------------------------|------------------------|-------------------------------|--------------------|--------------|--------------|
| EL3632P14LN   | 36 mm, 32 mm                         | #11, #10               |                               | 65 mm              | 207 mm       | 218 mm       |
| EL3832P14LN   | 38 mm, 32 mm                         |                        |                               | 70 mm              | 212 mm       | 223 mm       |
| EL4032P14LN   | 40 mm, 32 mm                         |                        |                               | 70 mm              | 221 mm       | 232 mm       |
| EL50T32P14LN  | 50 mm, 32 mm                         |                        |                               | 90 mm              | 287 mm       | 308 mm       |
| EL4030P14LN   | 40 mm, 30 mm                         |                        |                               | 70 mm              | 221 mm       | 232 mm       |
| EL4036P14LN   | 40 mm, 36 mm                         |                        |                               | 70 mm              | 221 mm       | 232 mm       |
| EL50T36P14LN  | 50 mm, 36 mm                         |                        |                               | 90 mm              | 287 mm       | 308 mm       |
| EL3430P14LN   | 34 mm, 30 mm                         |                        |                               | 60 mm              | 213 mm       | 224 mm       |
| EL3630P14LN   | 36 mm, 30 mm                         |                        |                               | 65 mm              | 207 mm       | 218 mm       |
| EL3634P14LN   | 36 mm, 34 mm                         |                        |                               | 65 mm              | 207 mm       | 218 mm       |
| EL3830P14LN   | 38 mm, 30 mm                         |                        |                               | 70 mm              | 212 mm       | 223 mm       |
| EL3836P14LN   | 38 mm, 36 mm                         | #12, #11               |                               | 70 mm              | 212 mm       | 223 mm       |
| EL3834P14LN   | 38 mm, 34 mm                         |                        |                               | 70 mm              | 212 mm       | 223 mm       |
| EL4038P14LN   | 40 mm, 38 mm                         |                        |                               | 70 mm              | 221 mm       | 232 mm       |
| EL50T38P14LN  | 50 mm, 38 mm                         |                        |                               | 90 mm              | 287 mm       | 308 mm       |
| EL4034P14LN   | 40 mm, 34 mm                         |                        |                               | 70 mm              | 221 mm       | 232 mm       |
| EL50T34P14LN  | 50 mm, 34 mm                         |                        |                               | 90 mm              | 287 mm       | 308 mm       |
| EL50T40P14LN  | 50 mm, 40 mm                         |                        |                               | 90 mm              | 287 mm       | 308 mm       |

Table 2/2

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand 1 (BG1) | Stababstand 2 (BG2) | Kupplungsgehäuse (CB) | Zertifizierungen                                                                   |
|---------------|----------------------|----------------------|---------------------|---------------------|-----------------------|------------------------------------------------------------------------------------|
| EL1210P14LN   | 19mm                 | 18mm                 | 61mm                | 68mm                | 46mm                  | DIBt, RISE, nVent LENTON EPD - Product Specific, Kontrollrådet, ITB                |
| EL1412P14LN   | 21mm                 | 19mm                 | 49mm                | 56mm                | 51mm                  | nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet, ITB, DIBt, RISE |
| EL1410P14LN   | 21mm                 | 18mm                 | 66mm                | 73mm                | 51mm                  | nVent LENTON EPD - Product Specific, Kontrollrådet, ITB                            |
| EL1614P14LN   | 24mm                 | 21mm                 | 47mm                | 53mm                | 54mm                  | DIBt, RISE, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet, ITB |
| EL1612P14LN   | 24mm                 | 19mm                 | 49mm                | 55mm                | 54mm                  | nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet, ITB, RISE       |
| EL1610P14LN   | 24mm                 | 18mm                 | 71mm                | 77mm                | 54mm                  | nVent LENTON EPD - Product Specific, Kontrollrådet, ITB                            |
| EL1816P14LN   | 29mm                 | 24mm                 | 44mm                | 50mm                | 61mm                  | nVent LENTON EPD - Product Specific, ITB                                           |
| EL1814P14LN   | 29mm                 | 21mm                 | 48mm                | 54mm                | 61mm                  | nVent LENTON EPD - Product Specific, ITB                                           |
| EL1812P14LN   | 29mm                 | 19mm                 | 61mm                | 67mm                | 61mm                  | nVent LENTON EPD - Product Specific, ITB                                           |

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand 1 (BG1) | Stababstand 2 (BG2) | Kupplungsgehäuse (CB) | Zertifizierungen                                                             |
|---------------|----------------------|----------------------|---------------------|---------------------|-----------------------|------------------------------------------------------------------------------|
| EL1810P14LN   | 29mm                 | 18mm                 | 78mm                | 84mm                | 61mm                  | nVent LENTON EPD - Product Specific, ITB                                     |
| EL2010P14LN   | 35mm                 | 18mm                 | 99mm                | 110mm               | 76mm                  | ITB, nVent LENTON EPD - Product Specific, Kontrollrådet                      |
| EL2012P14LN   | 35mm                 | 19mm                 | 88mm                | 99mm                | 76mm                  | nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet, ITB, RISE |
| EL2212P14LN   | 37mm                 | 19mm                 | 104mm               | 116mm               | 80mm                  | nVent LENTON EPD - Product Specific, ITB                                     |
| EL2512P14LN   | 40mm                 | 19mm                 | 110mm               | 121mm               | 86mm                  | nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet, ITB, RISE |
| EL2014P14LN   | 35mm                 | 21mm                 | 61mm                | 72mm                | 76mm                  | ITB, RISE, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet |
| EL2214P14LN   | 37mm                 | 21mm                 | 82mm                | 94mm                | 80mm                  | ITB, nVent LENTON EPD - Product Specific                                     |
| EL2514P14LN   | 40mm                 | 21mm                 | 103mm               | 114mm               | 86mm                  | ITB, RISE, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet |
| EL2814P14LN   | 42mm                 | 21mm                 | 112mm               | 124mm               | 90mm                  | ITB, nVent LENTON EPD - Product Specific                                     |
| EL2018P14LN   | 35mm                 | 29mm                 | 66mm                | 77mm                | 76mm                  | nVent LENTON EPD - Product Specific, ITB                                     |

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand 1 (BG1) | Stababstand 2 (BG2) | Kupplungsgehäuse (CB) | Zertifizierungen                                                                   |
|---------------|----------------------|----------------------|---------------------|---------------------|-----------------------|------------------------------------------------------------------------------------|
| EL2016P14LN   | 35mm                 | 24mm                 | 58mm                | 69mm                | 76mm                  | ITB, DIBt, RISE, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet |
| EL2216P14LN   | 37mm                 | 24mm                 | 96mm                | 108mm               | 80mm                  | nVent LENTON EPD - Product Specific, ITB                                           |
| EL2516P14LN   | 40mm                 | 24mm                 | 75mm                | 86mm                | 86mm                  | nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet, ITB, RISE       |
| EL2816P14LN   | 42mm                 | 24mm                 | 127mm               | 139mm               | 90mm                  | nVent LENTON EPD - Product Specific, ITB                                           |
| EL3016P14LN   | 52mm                 | 24mm                 | 122mm               | 133mm               | 102mm                 | nVent LENTON EPD - Product Specific                                                |
| EL2218P14LN   | 37mm                 | 29mm                 | 91mm                | 103mm               | 80mm                  | ITB, nVent LENTON EPD - Product Specific                                           |
| EL2518P14LN   | 40mm                 | 29mm                 | 105mm               | 116mm               | 86mm                  | ITB, nVent LENTON EPD - Product Specific                                           |
| EL2818P14LN   | 42mm                 | 29mm                 | 122mm               | 134mm               | 90mm                  | ITB, nVent LENTON EPD - Product Specific                                           |
| EL3018P14LN   | 52mm                 | 29mm                 | 140mm               | 151mm               | 102mm                 | nVent LENTON EPD - Product Specific                                                |
| EL3218P14LN   | 45mm                 | 29mm                 | 118mm               | 129mm               | 96mm                  | nVent LENTON EPD - Product Specific, ITB                                           |
| EL2220P14LN   | 37mm                 | 35mm                 | 68mm                | 80mm                | 80mm                  | ITB, nVent LENTON EPD - Product Specific                                           |

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand 1 (BG1) | Stababstand 2 (BG2) | Kupplungsgehäuse (CB) | Zertifizierungen                                                                   |
|---------------|----------------------|----------------------|---------------------|---------------------|-----------------------|------------------------------------------------------------------------------------|
| EL2520P14LN   | 40mm                 | 35mm                 | 115mm               | 126mm               | 86mm                  | ITB, DIBt, RISE, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet |
| EL2820P14LN   | 42mm                 | 35mm                 | 116mm               | 128mm               | 90mm                  | nVent LENTON EPD - Product Specific, ITB                                           |
| EL3020P14LN   | 52mm                 | 35mm                 | 128mm               | 139mm               | 102mm                 | nVent LENTON EPD - Product Specific                                                |
| EL3220P14LN   | 45mm                 | 35mm                 | 120mm               | 131mm               | 96mm                  | ITB, RISE, nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet       |
| EL3420P14LN   | 55mm                 | 35mm                 | 123mm               | 134mm               | 107mm                 | nVent LENTON EPD - Product Specific                                                |
| EL2522P14LN   | 40mm                 | 37mm                 | 111mm               | 122mm               | 86mm                  | nVent LENTON EPD - Product Specific, ITB                                           |
| EL2822P14LN   | 42mm                 | 37mm                 | 109mm               | 121mm               | 90mm                  | ITB, nVent LENTON EPD - Product Specific                                           |
| EL3022P14LN   | 52mm                 | 37mm                 | 126mm               | 137mm               | 102mm                 | nVent LENTON EPD - Product Specific                                                |
| EL3222P14LN   | 45mm                 | 37mm                 | 118mm               | 129mm               | 96mm                  | nVent LENTON EPD - Product Specific, ITB                                           |
| EL3422P14LN   | 55mm                 | 37mm                 | 136mm               | 147mm               | 107mm                 | nVent LENTON EPD - Product Specific                                                |
| EL3622P14LN   | 52mm                 | 37mm                 | 118mm               | 129mm               | 105mm                 | nVent LENTON EPD - Product Specific                                                |

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand 1 (BG1) | Stababstand 2 (BG2) | Kupplungsgehäuse (CB) | Zertifizierungen                                                             |
|---------------|----------------------|----------------------|---------------------|---------------------|-----------------------|------------------------------------------------------------------------------|
| EL3225P14LN   | 45mm                 | 40mm                 | 115mm               | 126mm               | 96mm                  | nVent LENTON EPD - Product Specific, Kontrollrådet, Kontrollrådet, ITB, RISE |
| EL3425P14LN   | 55mm                 | 40mm                 | 133mm               | 144mm               | 107mm                 | nVent LENTON EPD - Product Specific                                          |
| EL3625P14LN   | 52mm                 | 40mm                 | 125mm               | 136mm               | 105mm                 | nVent LENTON EPD - Product Specific                                          |
| EL3825P14LN   | 53mm                 | 40mm                 | 119mm               | 130mm               | 106mm                 | nVent LENTON EPD - Product Specific                                          |
| EL2825P14LN   | 42mm                 | 40mm                 | 106mm               | 118mm               | 90mm                  | ITB, DIBt, nVent LENTON EPD - Product Specific                               |
| EL3025P14LN   | 52mm                 | 40mm                 | 123mm               | 134mm               | 102mm                 | nVent LENTON EPD - Product Specific                                          |
| EL3028P14LN   | 52mm                 | 42mm                 | 121mm               | 132mm               | 102mm                 | nVent LENTON EPD - Product Specific                                          |
| EL4028P14LN   | 57mm                 | 42mm                 | 122mm               | 133mm               | 112mm                 | nVent LENTON EPD - Product Specific, ITB                                     |
| EL3228P14LN   | 45mm                 | 42mm                 | 113mm               | 124mm               | 96mm                  | ITB, DIBt, nVent LENTON EPD - Product Specific                               |
| EL3428P14LN   | 55mm                 | 42mm                 | 131mm               | 142mm               | 107mm                 | nVent LENTON EPD - Product Specific                                          |
| EL3628P14LN   | 52mm                 | 42mm                 | 123mm               | 134mm               | 105mm                 | nVent LENTON EPD - Product Specific                                          |
| EL3828P14LN   | 53mm                 | 42mm                 | 118mm               | 129mm               | 106mm                 | nVent LENTON EPD - Product Specific                                          |
| EL3230P14LN   | 45mm                 | 52mm                 | 103mm               | 114mm               | 96mm                  | nVent LENTON EPD - Product Specific                                          |

 
 
| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand 1 (BG1) | Stababstand 2 (BG2) | Kupplungsgehäuse (CB) | Zertifizierungen                                                    |
|---------------|----------------------|----------------------|---------------------|---------------------|-----------------------|---------------------------------------------------------------------|
| EL3432P14LN   | 55mm                 | 45mm                 | 128mm               | 139mm               | 107mm                 | nVent LENTON EPD - Product Specific                                 |
| EL3632P14LN   | 52mm                 | 45mm                 | 120mm               | 131mm               | 105mm                 | nVent LENTON EPD - Product Specific                                 |
| EL3832P14LN   | 53mm                 | 45mm                 | 115mm               | 126mm               | 106mm                 | nVent LENTON EPD - Product Specific                                 |
| EL4032P14LN   | 57mm                 | 45mm                 | 131mm               | 142mm               | 112mm                 | ITB, DIBt, RISE, nVent LENTON EPD - Product Specific, Kontrollrådet |
| EL50T32P14LN  | 70mm                 | 45mm                 | 172mm               | 193mm               | 148mm                 | nVent LENTON EPD - Product Specific                                 |
| EL4030P14LN   | 57mm                 | 52mm                 | 124mm               | 135mm               | 112mm                 | nVent LENTON EPD - Product Specific                                 |
| EL4036P14LN   | 57mm                 | 52mm                 | 124mm               | 135mm               | 112mm                 | nVent LENTON EPD - Product Specific                                 |
| EL50T36P14LN  | 70mm                 | 52mm                 | 180mm               | 201mm               | 148mm                 | nVent LENTON EPD - Product Specific                                 |
| EL3430P14LN   | 55mm                 | 52mm                 | 121mm               | 132mm               | 107mm                 | nVent LENTON EPD - Product Specific                                 |
| EL3630P14LN   | 52mm                 | 52mm                 | 113mm               | 124mm               | 105mm                 | nVent LENTON EPD - Product Specific                                 |
| EL3634P14LN   | 52mm                 | 55mm                 | 110mm               | 121mm               | 105mm                 | nVent LENTON EPD - Product Specific                                 |
| EL3830P14LN   | 53mm                 | 52mm                 | 108mm               | 119mm               | 106mm                 | nVent LENTON EPD - Product Specific                                 |
| EL3836P14LN   | 53mm                 | 52mm                 | 108mm               | 119mm               | 106mm                 | nVent LENTON EPD - Product Specific                                 |
| EL3834P14LN   | 53mm                 | 55mm                 | 105mm               | 116mm               | 106mm                 | nVent LENTON EPD - Product Specific                                 |

| Katalognummer | Einführtiefe 1 (BD1) | Einführtiefe 2 (BD2) | Stababstand 1 (BG1) | Stababstand 2 (BG2) | Kupplungsgehäuse (CB) | Zertifizierung                      |
|---------------|----------------------|----------------------|---------------------|---------------------|-----------------------|-------------------------------------|
| EL4038P14LN   | 57mm                 | 53mm                 | 123mm               | 134mm               | 112mm                 | nVent LENTON EPD - Product Specific |
| EL50T38P14LN  | 70mm                 | 53mm                 | 179mm               | 200mm               | 148mm                 | nVent LENTON EPD - Product Specific |
| EL4034P14LN   | 57mm                 | 55mm                 | 121mm               | 132mm               | 112mm                 | nVent LENTON EPD - Product Specific |
| EL50T34P14LN  | 70mm                 | 55mm                 | 177mm               | 198mm               | 148mm                 | nVent LENTON EPD - Product Specific |
| EL50T40P14LN  | 70mm                 | 57mm                 | 175mm               | 196mm               | 148mm                 | nVent LENTON EPD - Product Specific |

## ZUSÄTZLICHE PRODUKTDDETAILS

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMME



## WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter [www.nVent.com](http://www.nVent.com) sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.

#### **Nordamerika**

+1.800.753.9221

Option 1 – Kundendienst

Option 2 – Technischer

Support

#### **Europa**

Niederlande:

+31 800-0200135

Frankreich:

+33 800 901 793

#### **Europa**

Deutschland:

800 1890272

Sonstige Länder:

+31 13 5835404

#### **APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Unser starkes markenportfolio:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**