

T-Series Vertical Transition Filler Material Kit



T-Series vertical filler material kits contain the following: Filler material, two vertical packings, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

MERKMALE

Simplifies ordering

Used to splice different diameter bars

All components are for one-time use

SPEZIFIKATIONEN

Table 1/1

Katalognummer	Bewehrungsstabgröße, metrisch	Größe Armierung, USA	Größe Armierung, Kanada
RBT911101B	36 mm, 28 mm	#11, #9	35M, 30M
RBT910101B	32 mm, 28 mm	#10, #9	
RBT1114101B	43 mm, 36 mm	#14, #11	45M, 35M
RBT1118101B	57 mm, 36 mm	#18, #11	55M, 35M
RBT1011101B	36 mm, 32 mm	#11, #10	
RBT1418101B	57 mm, 43 mm	#18, #14	55M, 45M

ZUSÄTZLICHE PRODUKTDDETAILS


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Vertical Top Packing, (3) Vertical Bottom Packing, (4) Pouring Basin Ceramic Guide Tube, and (5) Crucible Ceramic and Disk.

Filler Material Kit Components				
Filler Material Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube
RBT910101B	RBF105	RBS354712 RBS35475.5	RBS5037	RBS5038
RBT911101B	RBF125	RBS354714 RBS35476	RBS5037	RBS5038
RBT1011101B	RBF125	RBS354712 RBS35476	RBS5037	RBS5038
RBT1114101B	RBF125	RBS354715 RBS35476	RBS5037	RBS5039
RBT1118101B	RBF240	RBS354712 RBS354720	RBS5037	RBS5039
RBT1418101B	RBF195	RBS354720 RBS35477	RBS5037	RBS5039

DIAGRAMME

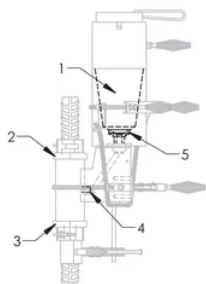

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.

Nordamerika

+1.800.753.9221

Option 1 – Kundendienst

Option 2 – Technischer

Support

Europa

Niederlande:

+31 800-0200135

Frankreich:

+33 800 901 793

Europa

Deutschland:

800 1890272

Sonstige Länder:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Unser starkes markenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE