
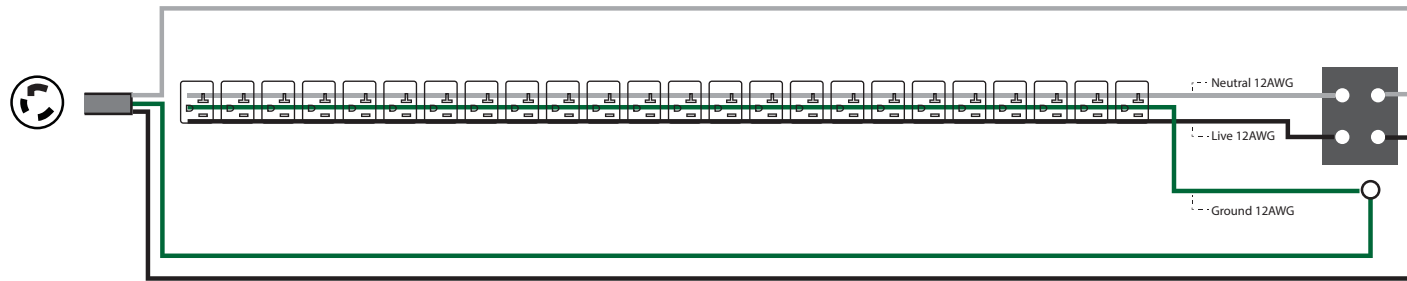


Basic Strip

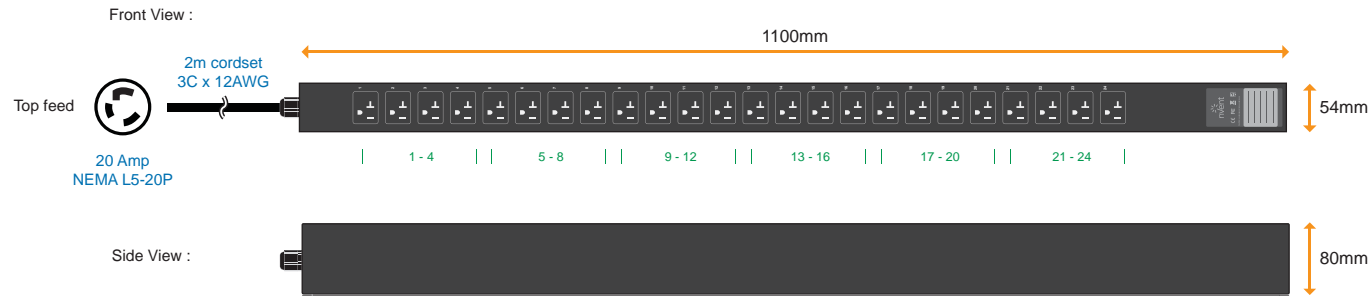

Single phase basic PDU

Input Rating : 20A, 110V
 Outlet : 20A Rated US NEMA 5-20R x 24
 Inlet : 20A NEMA L5-20P plug
 Cordset : 2 meter UL 12AWG cordset
 Protection : NIL
 Circuit Details : Output 16A max. U.S. # 1 - 24

Operating Temperature : -5 to 60 °C
 Storage Temperature : -25 to 65 °C
 Operating Altitude : 0 to 2,000 m
 Storage Altitude : 0 to 15,000 m
 Humidity : 8 to 95% RH, non-condensing

EMC Compliance : FCC Part 15 Subpart B certified
 Safety Compliance : cTUVus Mark to UL 60950-1:2007/R:2014-10
 CAN/CSA-C22.2 No. 60950-1:2007/A2:2014-10
 UL 62368-1:2014
 CAN/CSA-C22.2 No. 62368-1:2014
 UL 60730-1 Ed.5 (2016)

Environment Compliance : RoHS2 & REACH

Chassis Material : Steel
 Chassis Color : Black

Product Dimension : 2.1 (W) x 3.1 (D) x 43.3 (H) inch
 Net Weight : 16.1 lbs

Packing dimension (for 2 PDUs) : 4.3 (W) x 10.6 (D) x 54.8 (H) inch
 PDU gross weight (for 2 PDUs) : 39.95 lbs