


Combined Mounting Kit for Chassis

Energieversorger

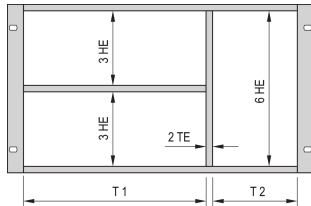

The combined mounting enable the option to split a 6 U high subrack or case in 2 x 3 U and 6 U sections. Different versions are available.

ZERTIFIZIERUNGEN



EIGENSCHAFTEN

Designed to accept Euroboards (100 mm high) and double Euroboards (233.35 mm high)

Subdivision of the 6 U assembly area into: 2 x 3 U, 1 x 6 U

SPEZIFIKATIONEN

Table 1/2

Katalognummer	Package Quantity	Rack Width 1	Rack Width 2	Product Family	Product Type	Rack Height
24562-484	1	84 HP		EuropacPRO	Mounting Kit	6 U
24562-420	1	20 HP	62 HP	EuropacPRO	Mounting Kit	6 U
24562-440	1	40 HP	42 HP	EuropacPRO	Mounting Kit	6 U
24562-442	1	42 HP	40 HP	EuropacPRO	Mounting Kit	6 U

Katalognummer	Package Quantity	Rack Width 1	Rack Width 2	Product Family	Product Type	Rack Height
24562-463	1	63 HP	19 HP	EuropacPRO	Mounting Kit	6 U

Table 2/2

Katalognummer	Typ	Kompatibel mit
24562-484	Combined	Baugruppenträger
24562-420	Combined	Baugruppenträger
24562-440	Combined	Baugruppenträger
24562-442	Combined	Baugruppenträger
24562-463	Combined	Baugruppenträger

ADDITIONAL PRODUCT DETAILS

Please order separately: Front panel 6 U, 2 HP to cover the strut.

The following guide rails cannot be used: type "accessory", type "accessory, strengthened" and type "for 4.4" PCB".

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE