


Front Panel Alternative for Combined Mounting, U-profile, Textile, 6 U, 2 HP

Power Utilities

KATALOGNUMMER

30849-140

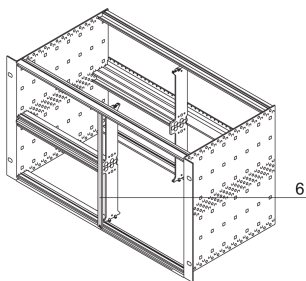

The 2 HP wide front panel covers an open slot. The U-profile front panel can be combined with a textile EMC gasket. It be fixed with screws and washers. Due to the 2 HP width no sleeves can be used.

ZERTIFIZIERUNGEN



MERKMALE

U-profile front panel 6 U, 2 HP, Al, 2.5 mm

Prepared for textile EMC gasket

PRODUKTMERKMALE

Produkttyp: Frontplatte

Frontbeschichtung: Eloxiert

Oberfläche Rückseite: Leitend

Behandelte Kanten: Nein

Höhe Gestell: 6 U

Anzahl Verpackungen: 5

ZUSÄTZLICHE PRODUKTDDETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Unser starkes markenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE