


RackPower iPDU, RP1326, 100-240 VAC, 1-phase

Power Utilities

KATALOGNUMMER

RP1326

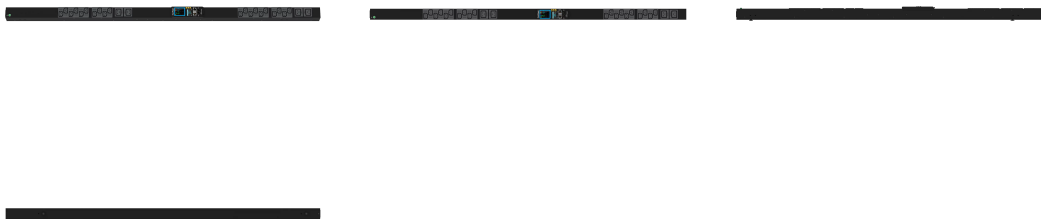

Modular, compact intelligent PDU with inlet metering. Ultra-Low Profile Design with only 44 mm height.

MERKMALE

RackPower RP1xxx Intelligent Power Distribution Units monitors input power of the entire PDU, provides billing grade unit level monitoring

High Visibility Data Display and Interactive Graphic Display

Measure circuit breaker loads across redundant feeds to avoid accidental downtime

Enables smart load balancing for power efficiency and maximized capacity utilization

Gigabit Ethernet Interface and redundant Ethernet (10/100)

iPDU DC power redundancy solution for up to 64 PDU's

Toolless Hot-Swap Controller

Input Voltage Range 100 - 240 VAC, 1-phase L-N or L-L

Input connector C20

C13, C19 outlets

PRODUKTMERKMALE

Produkttyp: Buchsenleiste

Typ Buchse: IEC C13; IEC C19

Farbe: Schwarz

Länge: 1490 mm

Spannung AC: 208 V

Funktion: Eingangsüberwacht

Tiefe: 53 mm

Breite: 52 mm

ZUSÄTZLICHE PRODUKTDDETAILS

Please order bracket for vertical mounting separately.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Unser starkes markenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE