


EuropacPRO Rugged Rear Angle for Textile EMC Gasket

Energieversorger

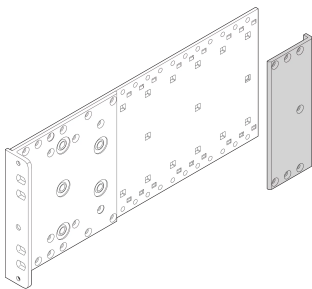

Corner profile covers the slot between the side panel and the rear panel of a subrack. Needed for a proper EMC shielding.

ZERTIFIZIERUNGEN



EIGENSCHAFTEN

Required for shielding of rear

Can also be used as front closure when using a depth-adjustable 19" support bracket

SPEZIFIKATIONEN

Table 1/2

Katalognummer	Rack Height	Package Quantity	Höhe	Product Family	Product Type	Typ
24566-499	6 U	1	265.9 mm	EuropacPRO	Abdeckung	Rugged
24566-197	3 U	1	132.6 mm	EuropacPRO	Abdeckung	Rugged

Katalognummer	Rack Height	Package Quantity	Höhe	Product Family	Product Type	Typ
24566-199	3 U	1	132.6 mm	EuropacPRO	Abdeckung	Rugged
24566-497	6 U	1	265.9 mm	EuropacPRO	Abdeckung	Rugged

Table 2/2

Katalognummer	Kompatibel mit	Verpackungseinheit	Zertifizierungen
24566-499	Baugruppenträger	Paar	RoHS
24566-197	Baugruppenträger	Paar	
24566-199	Baugruppenträger	Paar	RoHS
24566-497	Baugruppenträger	Paar	

ADDITIONAL PRODUCT DETAILS

Please order EMC textile gasket separately.

Corner profile cannot be used together with adapter for rear mounting.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE