


MultipacPRO 19" Chassis Basic Kit

Energieversorger

Such a kit enables a customer to configure the 3 different top / bottom covers.

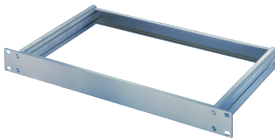

ZERTIFIZIERUNGEN



EIGENSCHAFTEN

For non-standardized assemblies (1 ... 5 U) and standardized assemblies (1, 2 U) conforming to IEC 60297-3-105

Frame consists of two lateral parts and front/rear panel

Werkstoff: aluminium

Select further components (Accessories)

SPEZIFIKATIONEN

Table 1/2

Katalognummer	Rack Height	Tiefe	Usable Width	Montage	Konform mit	EMC Shielding
20860-201	1 U	220 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-202	1 U	280 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)

Katalognummer	Rack Height	Tiefe	Usable Width	Montage	Konform mit	EMC Shielding
20860-203	1 U	340 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-204	1 U	400 mm	4 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-205	1 U	460 mm	4 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-210	2 U	220 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-211	2 U	280 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-212	2 U	340 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-213	2 U	400 mm	4 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-214	2 U	460 mm	4 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-219	3 U	280 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-220	3 U	340 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-221	3 U	400 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-222	3 U	460 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-228	4 U	280 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-229	4 U	340 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-230	4 U	400 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-231	4 U	460 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-240	5 U	460 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)

Table 2/2

Katalognummer	Product Family	Product Type	Typ	Zertifizierungen
---------------	----------------	--------------	-----	------------------

20860-201	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-202	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-203	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-204	MultipacPRO	Subrack/Chassis	Configurable	
20860-205	MultipacPRO	Subrack/Chassis	Configurable	
20860-210	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-211	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-212	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-213	MultipacPRO	Subrack/Chassis	Configurable	
20860-214	MultipacPRO	Subrack/Chassis	Configurable	
20860-219	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-220	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-221	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-222	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-228	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-229	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-230	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-231	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-240	MultipacPRO	Subrack/Chassis	Configurable	RoHS

ADDITIONAL PRODUCT DETAILS

Please order mounting plate, cover and base plates, handles, telescopic slides separately.

Dimensions h = clear mounting height = H-8.1 mm, b = clear mounting width = 403 mm.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE