


U-profile Front Panel, Shieldable, D-Sub Cutouts

Energieversorger

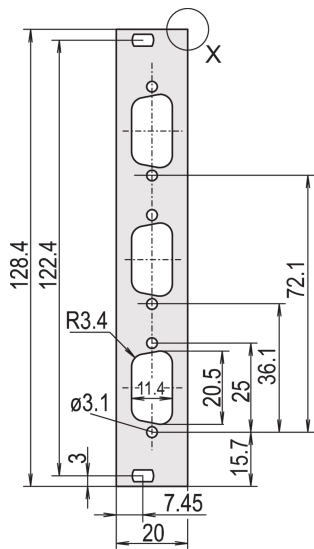

U-profile front panel with cutout for D-Sub connectors.
Shieldable for textile EMC gasket.

ZERTIFIZIERUNGEN



EIGENSCHAFTEN

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

SPEZIFIKATIONEN

Table 1/3

Katalognummer	Package Quantity	Montage	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
30849-749	5	Screw-on Front	Textile	Anodized	Conductive	Nein

Katalognummer	Package Quantity	Montage	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
30849-750	5	Screw-on Front	Textile	Anodized	Conductive	Nein
30849-751	5	Screw-on Front	Textile	Anodized	Conductive	Nein
30849-752	5	Screw-on Front	Textile	Anodized	Conductive	Nein
30849-753	5	Screw-on Front	Textile	Anodized	Conductive	Nein
30849-754	5	Screw-on Front	Textile	Anodized	Conductive	Nein
30849-755	5	Screw-on Front	Textile	Anodized	Conductive	Nein

Table 2/3

Katalognummer	Konform mit	EMC Shielding	Höhe	Material	Product Type	Rack Height
30849-749	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U
30849-750	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U
30849-751	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U
30849-752	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U
30849-753	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U
30849-754	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U
30849-755	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Frontplatte	3 U

Table 3/3

Katalognummer	Rack Width	Typ	Breite
---------------	------------	-----	--------

30849-749	4 HP	Front Panel without Handle	20 mm
30849-750	4 HP	Front Panel without Handle	20 mm
30849-751	4 HP	Front Panel without Handle	20 mm
30849-752	4 HP	Front Panel without Handle	20 mm
30849-753	4 HP	Front Panel without Handle	20 mm
30849-754	4 HP	Front Panel without Handle	20 mm
30849-755	4 HP	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE