


Modulschiene vorne, Typ H-KD, schwer, kurze Lippe, 40 TE

KATALOGNUMMER

34560-240

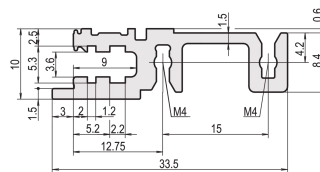

Combinations of horizontal rails and side panels

„+“ can be combined. „-“ combination not recommended

Support #	Horizontal rail	Side panel	Substrate	Substrate	Substrate	Substrate
Support #1		-	Substrate 1A (Solid)	Substrate 1B (Solid)	Substrate 1C (Solid)	Substrate 1D (Solid)
		+	Substrate 1A (Solid)	Substrate 1B (Solid)	Substrate 1C (Solid)	Substrate 1D (Solid)
Support #2		+	Substrate 2A (Solid)	Substrate 2B (Solid)	Substrate 2C (Solid)	Substrate 2D (Solid)
		+	Substrate 2A (Solid)	Substrate 2B (Solid)	Substrate 2C (Solid)	Substrate 2D (Solid)
Support #3		+	Substrate 3A (Solid)	Substrate 3B (Solid)	Substrate 3C (Solid)	Substrate 3D (Solid)
		+	Substrate 3A (Solid)	Substrate 3B (Solid)	Substrate 3C (Solid)	Substrate 3D (Solid)
Support #4		+	Substrate 4A (Solid)	Substrate 4B (Solid)	Substrate 4C (Solid)	Substrate 4D (Solid)
		+	Substrate 4A (Solid)	Substrate 4B (Solid)	Substrate 4C (Solid)	Substrate 4D (Solid)

Substrate 1A (Solid) Substrate 1B (Solid) Substrate 1C (Solid) Substrate 1D (Solid)
 Substrate 2A (Solid) Substrate 2B (Solid) Substrate 2C (Solid) Substrate 2D (Solid)
 Substrate 3A (Solid) Substrate 3B (Solid) Substrate 3C (Solid) Substrate 3D (Solid)
 Substrate 4A (Solid) Substrate 4B (Solid) Substrate 4C (Solid) Substrate 4D (Solid)

Modulschiene aus Aluminiumprofil vom Typ H-KD (H-KD = schwer, kurze Lippe) mit eloxierter Oberfläche und leitfähiger Kontaktfläche. Ohne Bedruckung (TE Markierung). Geeignet für RatiopacPRO/-AIR und EuropacPRO/-rugged)

ZERTIFIZIERUNGEN



MERKMALE

Einbau im Baugruppenträger kann oben und unten erfolgen

Kurze Lippe (H-KD)

Aluminiumprofil, Oberfläche eloxiert, Kontaktfläche leitfähig

PRODUKTMERKMALE

Breite Gestell: 40HP

Anzahl Verpackungen: 1

Oberfläche: Eloxiert

Länge: 208.28mm

Material: Aluminium

Produktfamilie: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Produkttyp: Modulschiene

Typ: Schwer, KD

Passt zu: Baugruppenträger; Gehäuse

ZUSÄTZLICHE PRODUKTDDETAILS

Die Lieferung erfolgt in Lieferlosgrößen. Die Preise gelten pro einzelnen Artikel.

Bitte beachten Sie, dass Lieferungen nur in den jeweils angegebenen LLG (Lieferlosgrößen), LLG z. B. 5 Stück, 10 Stück, 50 Stück usw.) möglich sind. Davon abweichende Bestellmengen (z. B. 2 Stück) werden auf die nächst mögliche lieferbare Menge = Lieferlosgröße (LLG) abgeändert.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Unser starkes markenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE