

# 300 Universal Beam Clamp



## CERTIFICATIONS



## FEATURES

Conforms with Federal Specification WW-H-171 (Type 23), Manufacturers Standardization Society (MSS) SP-58 (Type 19 and 23)

## SPECIFICATIONS

**Material:** Cast Iron

Table 1/2

Catalog Number	Finish	Flange Thickness (FT)	A	Torque (TQ)	Static Load 1 (F1)	Static Load 2 (F2)
3000037EG	Electrogalvanized	19.05 mm Max	28.5 mm	7 N·m	2200N	1100N
3000037PL	Plain	19.05 mm Max	28.58 mm	6.78 N·m	2200N	1100N
3000050EG	Electrogalvanized	19.05 mm Max	28.57 mm	10.85 N·m	4200N	3400N
3000050PL	Plain	19.05 mm Max	28.57 mm	10.85 N·m	4200N	3400N

CatalogNumber	Finish	Flange Thickness (FT)	A	Torque (TQ)	Static Load 1 (F1)	Static Load 2 (F2)
3000062EG	Electrogalvanized	19.05 mm Max	28.57 mm	6.78 N·m	4200N	3400N
3000062PL	Plain	19.05 mm Max	28.57 mm	6.78 N·m	4200N	3400N
3000075EG	Electrogalvanized	19.05 mm Max	28.57 mm	6.78 N·m	4200N	3400N
3000075PL	Plain	19.05 mm Max	28.57 mm	6.78 N·m	4200N	3400N
3000087EG	Electrogalvanized	19.05 mm Max	28.57 mm	6.78 N·m	4200N	3400N
3000087PL	Plain	19.05 mm Max	28.57 mm	6.78 N·m	4200N	3400N


Table 2/2

Catalog Number	Certifications
3000037EG	cUL, FM Approved, Pipe Hanger Components, UL
3000037PL	FM Approved, Pipe Hanger Components, UL, cUL
3000050EG	cUL, FM Approved, Pipe Hanger Components, UL
3000050PL	UL, cUL, FM Approved, Pipe Hanger Components
3000062EG	UL, cUL
3000062PL	UL, cUL
3000075EG	cUL, UL
3000075PL	UL, cUL
3000087EG	cUL, UL
3000087PL	UL, cUL

ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

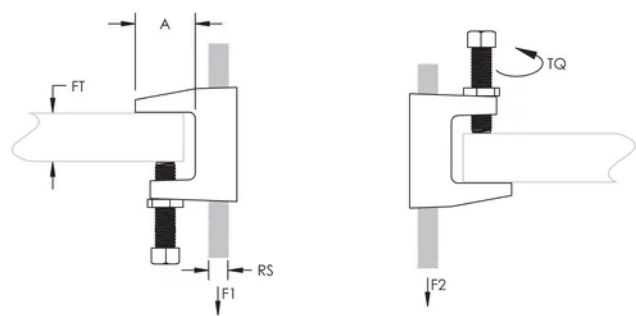

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

