

KP T-Bolt for C-Channel E4



FEATURES

For use with C-Profiles

Pre-mounted with large washer and nut

SPECIFICATIONS

Channel Type: E4
Finish: Electrogalvanized
Material: Steel

Table 1/1


Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	A	B
KP3808040	590210	8	40mm	30 mm	23 mm
KP3810050	590330	10	50mm	30 mm	23 mm
KP3810035	590207	10	35mm	30 mm	23 mm
KP3808025	590201	8	25mm	30 mm	23 mm

ADDITIONAL PRODUCT DETAILS

Sliding force F2 is limited to 600 N for all types of Nuts and T-Bolts for C-channel System.

Nuts and T-Bolts for C-channel System	
C-Channel Type	Pullout Force F1
E4	2600 N

DIAGRAMS

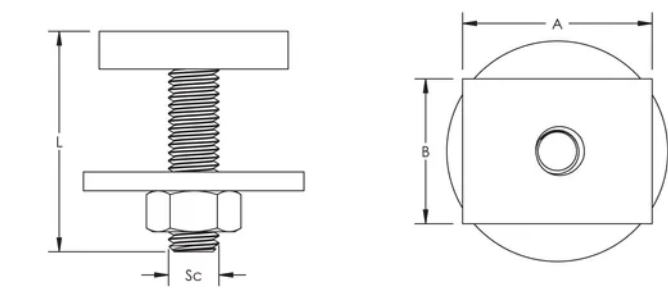

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

