

# PESHTS Heavy Duty Pipe Slide with Strap, Two Connectors



## FEATURES

For use with two pipe clamps


Includes welded on mounting strap

## SPECIFICATIONS

Catalog Number	PESHTS
Article Number	580567
Material	Steel
Finish	Electrogalvanized
Rod Size (RS)	M12 M16
Height (H)	57 mm
Length (L)	275mm
$\Delta$ Length ( $\Delta L$ )	245 mm
Width (W)	188 mm
A	160 mm
B	40 mm
C	210 mm
X	13 x 25 mm

Catalog Number	PESHTS
Temperature	240 °C Max
Static Load 1 (F1)	9000N
Static Load 2 (F2)	5000N

### DIAGRAMS

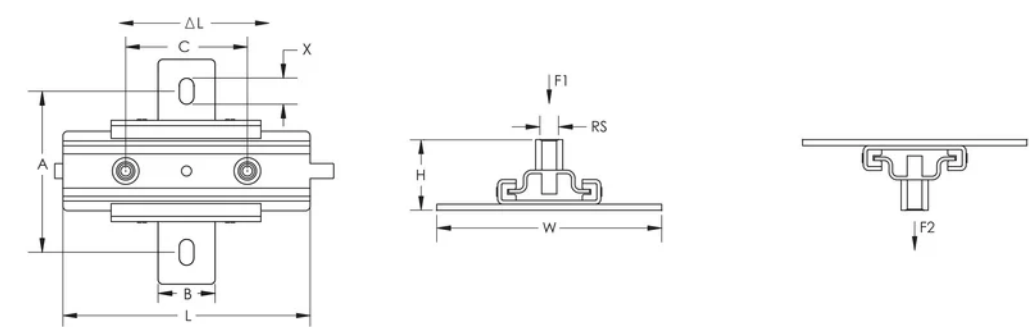

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

