

# RTU Ball Swivel



## FEATURES

Swivels up to 15°

## SPECIFICATIONS


**Finish:** Electrogalvanized

**Material:** Steel

Table 1/1

Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	Height (H)	Static Load
RTUM8	583580	8	15mm	56 mm	2500N
RTUM8L15	583600	8	15mm	66 mm	2500N
RTUM10	583590	10	18mm	75 mm	2500N
RTUM10L18	583610	10	18mm	85 mm	2500N
RTUM12L20	583620	12	20mm	95 mm	3000N
RTUM10L30	583630	10	30mm	85 mm	2500N

DIAGRAMS

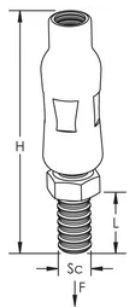

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

