


# E650C-G Ground Sensor for Elexant 650c-Modbus

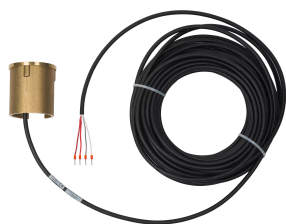

Ground sensor for combined measurement of temperature and moisture values in outdoor areas with foot or vehicle traffic. Robust version made of brass, fully encapsulated. Very low installation height, so particularly well suited to staircases, terraces, etc.

## FEATURES

Cable connection: To the side

Connection cable: 4 x 0.5 mm<sup>2</sup>

Temperature range for moisture measurement: -20°C to 30°C

## SPECIFICATIONS

Table 1/2

Catalog Number	Item Name	Communication	Diameter	Hazardous Area	Height	IP Rating
1244-022796	RAYSENS-SSM-20-HOUSING	No	68 mm	No	31 mm	IP68
1244-022794	RAYSENS-SSM-20	No	68 mm	No	72 mm	IP68

Table 2/2

Catalog Number	Item Name	Measuring Range
1244-022796	RAYSENS-SSM-20-HOUSING	
1244-022794	RAYSENS-SSM-20	-20 to 30 °C

## **WARNING**

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### **North America**

Tel +1.800.545.6258

Fax +1.800.527.5703

[thermal.info@nvent.com](mailto:thermal.info@nvent.com)

### **Europe, Middle East, Africa**

Tel +32.16.213.511

Fax +32.16.213.604

[thermal.info@nvent.com](mailto:thermal.info@nvent.com)

### **Asia Pacific**

Tel +86.21.2412.1688

Fax +86.21.5426.3167

[cn.thermal.info@nvent.com](mailto:cn.thermal.info@nvent.com)

### **Latin America**

Tel +1.713.868.4800

Fax +1.713.868.2333

[thermal.info@nvent.com](mailto:thermal.info@nvent.com)

Our powerful portfolio of brands:

**RAYCHEM PYROTENAX TRACER NUHEAT**