


19" Front Panel, Vented

Vented front panels allows heat dissipation through holes.

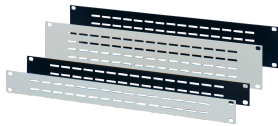

CERTIFICATIONS



FEATURES

Vented front panels (Aluminum) allows heat dissipation

SPECIFICATIONS

Rack Width:	95HP
Material:	Aluminum
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/3

Catalog Number	Rack Height	Finish	Mounting	Package Quantity	Front Finish	Rear Finish
30118-962	1U	Powder Coated	Screw-on Front	1	Painted	Painted
30702-044	1U	Anodized	Screw-on Front	1	Raw	Conductive
30702-047	1U	Anodized	Screw-on Front	1	Anodized	Anodized

CatalogNumber	Rack Height	Finish	Mounting	Package Quantity	Front Finish	Rear Finish
30702-056	1U	Powder Coated	Screw-on Front	1	Painted	Painted
30118-963	2U	Anodized	Screw-on Front	1	Painted	Painted
30702-045	2U	Anodized	Screw-on Front	1	Raw	Raw
30702-048	2U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-057	2U	Powder Coated	Screw-on Front	1	Painted	Painted
30118-964	3U	Powder Coated	Screw-on Front	1	Painted	Painted
30702-046	3U	Anodized	Screw-on Front	1	Raw	Raw
30702-049	3U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-058	3U	Powder Coated	Screw-on Front	1	Painted	Painted

Table 2/3

Catalog Number	Treated Edges	Color Code	EMC Shielding	Height (H)	Type	Width (W)
30118-962		RAL 7021	No	43.6mm	19" Front Panel	483mm
30702-044			No	43.6mm	19" Front Panel	483mm
30702-047	Yes		No	43.6mm	19" Front Panel	483mm
30702-056		RAL 7035	No	43.6mm	19" Front Panel	483mm
30118-963		RAL 7021	No	88.1mm	19" Front Panel	483mm
30702-045			No	88.1mm	19" Front Panel	483mm
30702-048	Yes		No	88.1mm	19" Front Panel	483mm

CatalogNumber	Treated Edges	Color Code	EMC Shielding	Height (H)	Type	Width (W)
30702-057		RAL 7035	No	88.1mm	19" Front Panel	483mm
30118-964		RAL 7021	No	132.5mm	19" Front Panel	483mm
30702-046			No	132.5mm	19" Front Panel	483mm
30702-049	Yes		No	132.5mm	19" Front Panel	483mm
30702-058		RAL 7035	No	132.5mm	19" Front Panel	483mm


Table 3/3

Catalog Number	Quick Ship
30118-962	No
30702-044	No
30702-047	No
30702-056	No
30118-963	No
30702-045	No
30702-048	No
30702-057	No
30118-964	No
30702-046	No
30702-049	No
30702-058	No

ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

DIAGRAMS

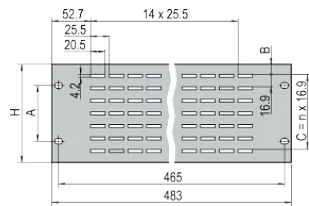

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE