


PSU 19" DC/DC Coolpower 100 W, Triple, CPDC 312

CATALOG NUMBER

13103-016

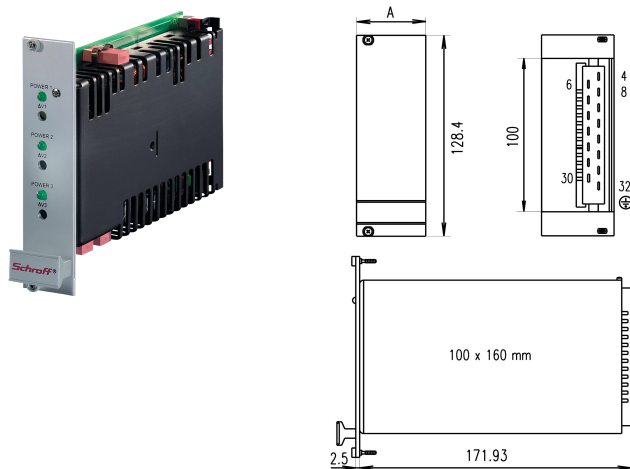

Pluggable 19" Power Supplies with H15 connector for fanless applications.

CERTIFICATIONS



FEATURES

Wide input voltage range from 20 to 72 VDC

Galvanic separation between primary and secondary circuits

High power density

External ON/OFF

PRODUCT ATTRIBUTES

Product Type: Power Supply

Type: 19" DC/DC Converter

Input Voltage DC: 20 – 72V

Power: 98W

Number of Output Voltages: 3

Voltage 1: 5V

Current 1: 10A

Voltage 2: 12V

Current 2: 2A

Voltage 3: 12V

Current 3: 2A

Rack Height: 3U

Rack Width: 6HP

Gross Weight: 0.585kg

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

For Input voltage 100-360 VDC see AC/DC Switched mode power supply.

Please order front panel separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE