

# Plug-In Unit U-Profile Front Panel for XL Handle

Front panel for XL handle. Shieldable with textile gasket. with or without cutout for a microswitch.



## CERTIFICATIONS



## FEATURES

Al, front anodized, sides and rear conductive

Suitable for sleeve and collar screw

U-front profile, shieldable, for inserter/extractor handle, type XL

## SPECIFICATIONS

|                        |                              |
|------------------------|------------------------------|
| <b>Material:</b>       | Aluminum                     |
| <b>Finish:</b>         | Anodized; Passivated         |
| <b>Accessory Type:</b> | Front panel                  |
| <b>Product Type:</b>   | Front Panel                  |
| <b>Type:</b>           | Front Panel for Handle (PIU) |
| <b>EMC Shielding:</b>  | No (Retrofittable)           |

Table 1/3

| Catalog Number | Rack Width | Package Quantity | Handle Type | Mounting       | Gasket Type | Front Finish |
|----------------|------------|------------------|-------------|----------------|-------------|--------------|
| 30849-153      | 4HP        | 1                | XL          | Screw-on Front | Textile EMC | Anodized     |

| CatalogNumber | Rack Width | Package Quantity | Handle Type | Mounting       | Gasket Type | Front Finish |
|---------------|------------|------------------|-------------|----------------|-------------|--------------|
| 30849-154     | 4HP        | 1                | XL          | Screw-on Front | Textile EMC | Anodized     |
| 30849-156     | 8HP        | 1                | XL          | Screw-on Front | Textile EMC | Anodized     |
| 30849-155     | 8HP        | 1                | XL          | Screw-on Front | Textile EMC | Anodized     |
| 30849-158     | 12HP       | 1                | XL          | Screw-on Front | Textile EMC | Anodized     |
| 30849-157     | 12HP       | 1                | XL          | Screw-on Front | Textile EMC | Anodized     |

Table 2/3

| Catalog Number | Rear Finish | Treated Edges | Complies With                   | Depth (D) | Height (H) | Rack Height |
|----------------|-------------|---------------|---------------------------------|-----------|------------|-------------|
| 30849-153      | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/11 | 2.5mm     | 261.8mm    | 6U          |
| 30849-154      | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/11 | 2.5mm     | 261.8mm    | 6U          |
| 30849-156      | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/11 | 2.5mm     | 261.8mm    | 6U          |
| 30849-155      | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/11 | 2.5mm     | 261.8mm    | 6U          |
| 30849-158      | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/11 | 2.5mm     | 261.8mm    | 6U          |
| 30849-157      | Conductive  | No            | IEC 60297-3-101, IEEE 1101.1/11 | 2.5mm     | 261.8mm    | 6U          |

Table 3/3

| Catalog Number | Width (W) | Quick Ship |
|----------------|-----------|------------|
| 30849-153      | 20mm      | No         |
| 30849-154      | 20mm      | No         |
| 30849-156      | 40.3mm    | No         |


| Catalog Number | Width (W) | Quick Ship |
|----------------|-----------|------------|
| 30849-155      | 40.3mm    | No         |
| 30849-158      | 60.6mm    | No         |
| 30849-157      | 60.6mm    | No         |

## ADDITIONAL PRODUCT DETAILS

Delivery is exclusively in standard pack quantity, Please order EMC textile gasket and microswitch separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## DIAGRAMS

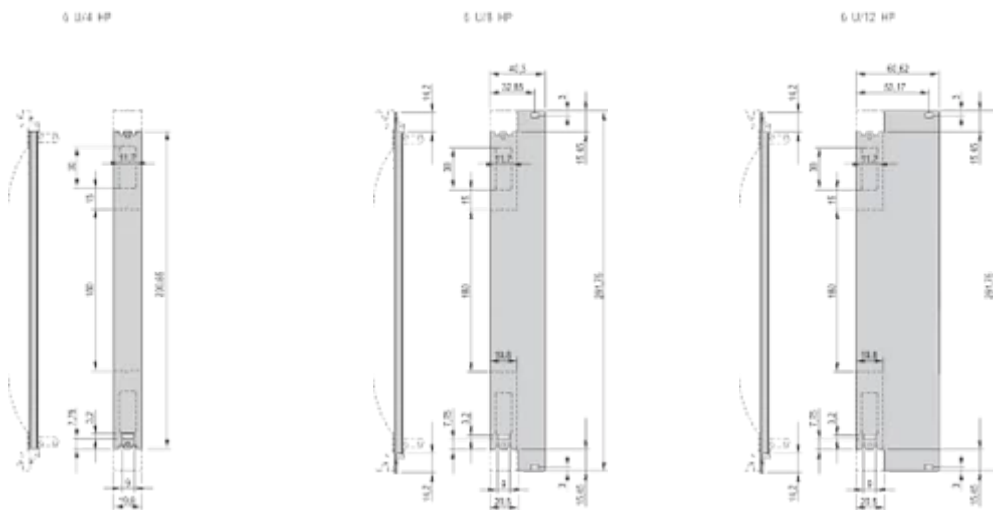

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**