


# RatiopacPRO AIR Radial Fan Unit

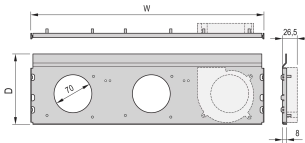

Simple mountable radial Fan Unit for RatiopacPRO AIR, with a air capacity of 36 m³/h (free blowing) per fan. Available in 4 widths and 2 depths and with up to 3 fans equipped.

## CERTIFICATIONS



## FEATURES

Ball-bearing radial fans

Air capacity 36 m³/h (free blowing) per fan

Fits for RatiopacPRO Air cases (fan unit needs only 0,5 U height)

Only 1/2 U height

Air exhaust via perforation in cover plate

No restriction to rear mounting space

No mechanical modification of the case necessary

Simple mounting

## SPECIFICATIONS

|                        |                 |
|------------------------|-----------------|
| <b>Material:</b>       | Aluminum        |
| <b>Works With:</b>     | Cases           |
| <b>Product Type:</b>   | Fan             |
| <b>Type:</b>           | Radial Fan      |
| <b>Product Family:</b> | RatiopacPRO AIR |

Table 1/1

| Catalog Number | Rack Width | Voltage DC | Airflow | Depth | Width | Quick Ship |
|----------------|------------|------------|---------|-------|-------|------------|
|----------------|------------|------------|---------|-------|-------|------------|

|           |      |     |        |       |          |    |
|-----------|------|-----|--------|-------|----------|----|
| 24572-404 | 28HP | 12V | 36m³/h | 160mm | 146.87mm | No |
| 24572-405 | 42HP | 12V | 36m³/h | 160mm | 218mm    | No |
| 24572-408 | 28HP | 12V | 36m³/h | 220mm | 146.87mm | No |
| 24572-409 | 42HP | 12V | 36m³/h | 220mm | 218mm    | No |
| 24572-406 | 63HP | 12V | 36m³/h | 160mm | 324.67mm | No |
| 24572-410 | 63HP | 12V | 36m³/h | 220mm | 324.67mm | No |
| 24572-407 | 84HP | 12V | 36m³/h | 160mm | 431.35mm | No |
| 24572-411 | 84HP | 12V | 36m³/h | 220mm | 431.35mm | No |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**