

nVent CADDY Speed Link SLK with Angle Bracket



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled angle bracket end fitting

Ideal for attaching to concrete, steel or wood surfaces

Simple alternative to jack chain and additional hardware

SPECIFICATIONS

Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Zinc Alloy;Polypropylene
Complies With:	SMACNA HVAC-DCS

Table 1/2


Catalog Number	Article Number	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)	Height (H)
SLK3L5AB	196715	3 mm	5m	22.6 mm	7.1 mm	62 mm

CatalogNumber	Article Number	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)	Height (H)
SLK3L10AB	196716	3 mm	10m	22.6 mm	7.1 mm	62 mm
SLK15L2AB	196501	1.5 mm	2m	22.6 mm	7.1 mm	55 mm
SLK2L2AB	196529	2 mm	2m	22.6 mm	7.1 mm	55 mm
SLK2L3AB	196530	2 mm	3m	22.6 mm	7.1 mm	55 mm
SLK3L7AB	196728	3 mm	7m	22.6 mm	7.1 mm	62 mm
SLK15L1AB	196500	1.5 mm	1m	22.6 mm	7.1 mm	55 mm
SLK2L5AB	196531	2 mm	5m	22.6 mm	7.1 mm	55 mm
SLK15L5AB	196503	1.5 mm	5m	22.6 mm	7.1 mm	55 mm
SLK15L3AB	196502	1.5 mm	3m	22.6 mm	7.1 mm	55 mm

Table 2/2						
Catalog Number	Article Number	Width (W)	Thickness (T)	Angle (a)	Static Load	Certifications
SLK3L5AB	196715	24 mm	16 mm	90 ° Max	890N	
SLK3L10AB	196716	24 mm	16 mm	90 ° Max	890N	
SLK15L2AB	196501	19 mm	12.5 mm	90 ° Max	195N	UL, cUL, ITB
SLK2L2AB	196529	19 mm	12.5 mm	90 ° Max	440N	ITB, cUL, UL
SLK2L3AB	196530	19 mm	12.5 mm	90 ° Max	440N	cUL, UL, ITB
SLK3L7AB	196728	24 mm	16 mm	90 ° Max	890N	
SLK15L1AB	196500	19 mm	12.5 mm	90 ° Max	195N	ITB, UL, cUL

CatalogNumber	Article Number	Width (W)	Thickness (T)	Angle (a)	Static Load	Certifications
SLK2L5AB	196531	19 mm	12.5 mm	90 ° Max	440N	cUL, UL, ITB
SLK15L5AB	196503	19 mm	12.5 mm	90 ° Max	195N	ITB, cUL, UL
SLK15L3AB	196502	19 mm	12.5 mm	90 ° Max	195N	UL, cUL, ITB

DIAGRAMS

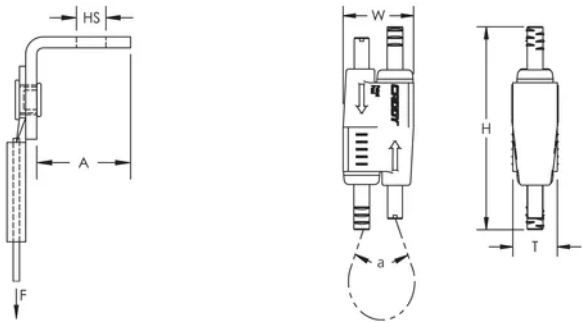

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

