

Fence Clamp for Field-Welded Connections



FEATURES

Ideal for when nVent ERICO Cadweld connections cannot be made to aluminum pipe or thin-wall steel tube

Stainless steel hardware included

Can be used when field-welding conductors

SPECIFICATIONS

Material: Electrolytic Copper

Finish: Tinned


Table 1/1

Catalog Number	Fence Post Size, Nominal	Fence Post Outside Diameter, Actual (Ø)
B522B	1 1/4"	42 mm
B522C	1 1/2"	48 mm
B522D	2"	60 mm
B522E	2 1/2"	73 mm
B522F	3"	89 mm

Catalog Number	Fence Post Size, Nominal	Fence Post Outside Diameter, Actual (Ø)
B522G	3 1/2"	102 mm
B522H	4"	114 mm
B522K	6"	168 mm

Common Connection Components for Field Assembly		
Conductor Size	ERICO CADWELD Mold Part Number	Welding Material
1/0 Concentric	LAC2C002	65
2/0 Concentric	LAC2G002	65
4/0 Concentric	LAC2Q002	90

DIAGRAMS

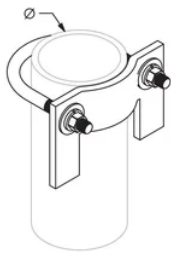

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE