

Stainless Steel Ground Rod, Threaded



CERTIFICATIONS



FEATURES

Utilizes a cut thread for highly corrosive soil

SPECIFICATIONS

Material: Stainless Steel 304 (EN 1.4301)


Tensile Strength: 483 MPa Min

Table 1/1

Catalog Number	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Thread Size (TS)	Length (L)	Unit Weight	Certifications
685800S	5/8"	16 mm	5/8" UNC	3.05mm	4.7 kg	UL, cUL
685880S	5/8"	16 mm	5/8" UNC	2.44mm	3.5 kg	UL, RUS
683400S	3/4"	19.1 mm	3/4" UNC	3.05mm	6.8 kg	cUL, UL

CatalogNumber	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Thread Size (TS)	Length (L)	Unit Weight	Certifications
683450S	3/4"	19.1 mm	3/4" UNC	1.52mm	3.1 kg	
684400S	1"	25.4 mm	1" UNC	3.05mm	12.1 kg	

DIAGRAMS

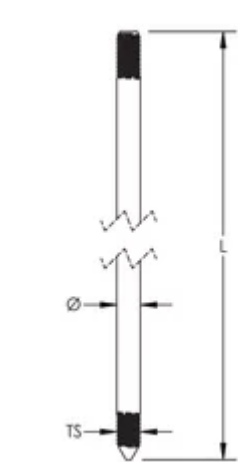

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE