


# Front Panel 2 HP Wide for Combined Mounting

## Power Utilities

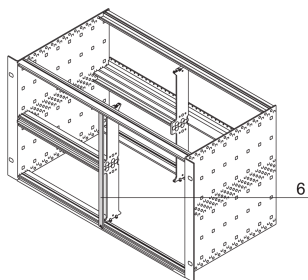

The 2 HP wide front panel covers an open slot. The non-shielded version can be fixed with screws and washers. Due to the 2 HP width, no sleeves can be used.

## CERTIFICATIONS



## FEATURES

Flat front panel 6 U, 2 HP, Al, 2.5 mm

## SPECIFICATIONS

| Table 1/1      |              |             |               |             |                  |
|----------------|--------------|-------------|---------------|-------------|------------------|
| Catalog Number | Front Finish | Rear Finish | Treated Edges | Rack Height | Package Quantity |
| 30847-472      | Anodized     | Conductive  | No            | 6 U         | 5                |

## ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**