


# Novastar 19" Panel/Slide Mount

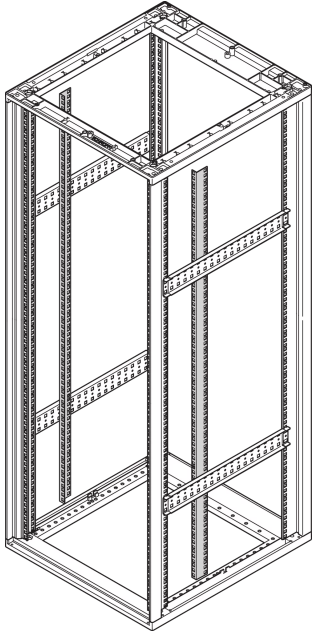

Novastar 19" Panel/Slide Mount Kit with load capacity of 400 kg, ensures easy fitting of 19" components to depth members.

## CERTIFICATIONS

---



## FEATURES

---

For recessed installation of 19" components

For fitting to depth members (25 mm grid)

Load carrying capacity 400 kg

## SPECIFICATIONS

---

**Product Type:** Slide Mount

**Material:** Steel

Table 1/2

| Catalog Number | Rack Height | Package Quantity | Color      | Color Code | Finish        | Height    |
|----------------|-------------|------------------|------------|------------|---------------|-----------|
| 27230-172      | 6U          | 2                | Black Grey | RAL 7021   | Powder Coated | 267.1mm   |
| 27230-173      | 9U          | 2                | Black Grey | RAL 7021   | Powder Coated | 400.45mm  |
| 27230-174      | 12U         | 2                | Black Grey | RAL 7021   | Powder Coated | 533.8mm   |
| 27230-175      | 16U         | 2                | Black Grey | RAL 7021   | Powder Coated | 711.6mm   |
| 27230-176      | 20U         | 2                | Black Grey | RAL 7021   | Powder Coated | 889.4mm   |
| 27230-177      | 25U         | 2                | Black Grey | RAL 7021   | Powder Coated | 1111.65mm |
| 27230-197      | 29U         | 2                | Black Grey | RAL 7021   | Powder Coated | 1291mm    |
| 27230-178      | 34U         | 2                | Black Grey | RAL 7021   | Powder Coated | 1511.7mm  |
| 27230-179      | 38U         | 2                | Black Grey | RAL 7021   | Powder Coated | 1689.5mm  |
| 27230-180      | 43U         | 2                | Black Grey | RAL 7021   | Powder Coated | 1911.75mm |
| 27230-181      | 47U         | 2                | Black Grey | RAL 7021   | Powder Coated | 2089.55mm |

Table 2/2

| Catalog Number | Package Unit | Certifications | Quick Ship |
|----------------|--------------|----------------|------------|
| 27230-172      | Pair         | RoHS           | No         |
| 27230-173      | Pair         | RoHS           | No         |
| 27230-174      | Pair         | RoHS           | No         |
| 27230-175      | Pair         | RoHS           | No         |
| 27230-176      | Pair         | RoHS           | No         |

| Catalog Number | Package Unit | Certifications | Quick Ship |
|----------------|--------------|----------------|------------|
| 27230-177      | Pair         | RoHS           | No         |
| 27230-197      |              |                | No         |
| 27230-178      | Pair         | RoHS           | No         |
| 27230-179      | Pair         | RoHS           | No         |
| 27230-180      | Pair         | RoHS           | No         |
| 27230-181      | Pair         | RoHS           | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**