


# 19" Front Panel, Vented, 2 U, 2.5 mm, Al, Anodized

## Data Solutions

### CATALOG NUMBER

**30702-048**

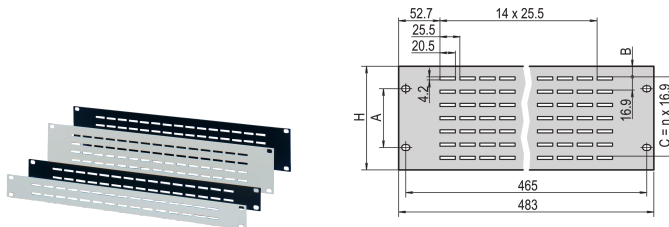

Vented front panels allows heat dissipation through holes.

### CERTIFICATIONS



### FEATURES

Vented front panels (Aluminum ) allows heat dissipation

### PRODUCT ATTRIBUTES

Rack Height: 2U

Accessory Type: Front panel

Finish: Anodized

Mounting: Screw-on Front

Package Quantity: 1

Front Finish: Anodized

Rear Finish: Anodized

Treated Edges: Yes

EMC Shielding: No

Height (H): 88.1mm

Material: Aluminum

Product Type: Front Panel

Rack Width: 95HP

Type: 19" Front Panel


Width (W): 483mm

Net Weight: 0.247kg

## ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

## DIAGRAMS

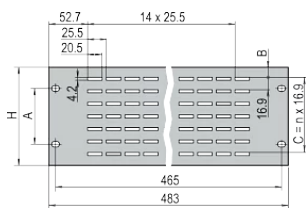

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**