

# Ground Rod Clamp with Prefabricated Pigtail



## FEATURES

Prefabricated assembly including grounding clamp with pigtail

Fast and simple installation requires only a hammer

## SPECIFICATIONS

**Material:** Copper


**Insulation:** Green and Yellow Insulated Cable

Table 1/1

Catalog Number	Article Number	Ground Rod Diameter, Nominal	Length (L)	Pigtail Length	Conductor Size	Unit Weight
EPT1225300	158610	1/2"	70mm	300mm	25 mm <sup>2</sup> Stranded	0.5 kg
EPT1425350	158675	5/8"	75mm	350mm	25 mm <sup>2</sup> Stranded	0.5 kg
EPT1450350	158290	5/8"	75mm	350mm	50 mm <sup>2</sup> Stranded	0.5 kg

## DIAGRAMS

---

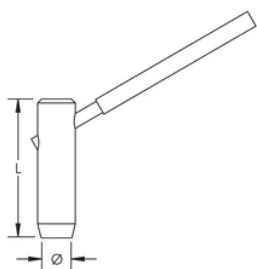

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**