


AMC Filler Module With Pull-Handle

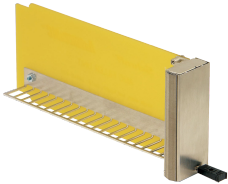

This AdvancedMC filler module consists of a stainless steel front panel without LEDs and has EMC gaskets on the left hand and bottom side. The filler module is fixed into the chassis card guide by a snap in plastic nose. The module can be used to cover an empty slot, to ensure EMC shielding and close the front to seal air leaks into the chassis. These filler modules can be used in AdvancedMC Carriers and in MicroTCA slots. It doesn't require a locking bar.

CERTIFICATIONS



FEATURES

In accordance with AMC.0 R2.0 specification

Shielded filler modules are used to close unused slots

pull handle to extract sub-assembly

The optional air baffle (airflow adjustable) can be used to direct chassis airflow

SPECIFICATIONS

- Product Family:** AdvancedMC
- Type:** Filler Module
- Product Type:** System Module

Table 1/1

Catalog Number	Design Feature	Material	Finish	Package Quantity	Quick Ship
20849-248	Mid-Size	Aluminum	Passivated	1	No
20849-024	Full-Size	Stainless Steel		1	No

Catalog Number	Design Feature	Material	Finish	Package Quantity	Quick Ship
20849-022	Compact	Stainless Steel		1	No
20849-250	Full-Size	Aluminum	Passivated	1	No
20849-106	Mid-Size	Stainless Steel		1	No
20849-251	Full-Size	Aluminum	Passivated	1	No
20849-107	Mid-Size	Stainless Steel		1	No
20849-025	Full-Size	Stainless Steel		1	No
20849-249	Mid-Size	Aluminum	Passivated	1	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE