


# Inpac Front Panel

The front panel can be assembled on to the Inpac Case.

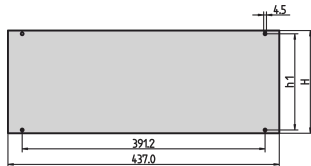

## CERTIFICATIONS



## FEATURES

Al panel, 2.5 mm

## SPECIFICATIONS

|                        |             |
|------------------------|-------------|
| <b>Depth:</b>          | 2.5mm       |
| <b>Material:</b>       | Aluminum    |
| <b>Finish:</b>         | Anodized    |
| <b>Works With:</b>     | Cases       |
| <b>Accessory Type:</b> | Front panel |
| <b>Product Type:</b>   | Front Panel |
| <b>Product Family:</b> | Inpac       |

Table 1/2

| Catalog Number | Rack Height | Package Quantity | Front Finish | Rear Finish | Treated Edges | EMC Shielding |
|----------------|-------------|------------------|--------------|-------------|---------------|---------------|
| 30828-055      | 2U          | 1                | Anodized     | Anodized    | No            | No            |
| 30828-058      | 3U          | 1                | Anodized     | Anodized    | No            | No            |
| 30828-061      | 4U          | 1                | Anodized     | Anodized    | No            | No            |

| CatalogNumber | Rack Height | Package Quantity | Front Finish | Rear Finish | Treated Edges | EMC Shielding |
|---------------|-------------|------------------|--------------|-------------|---------------|---------------|
| 30828-067     | 6U          | 1                | Anodized     | Anodized    | No            | No            |

| Table 2/2      |         |       |            |
|----------------|---------|-------|------------|
| Catalog Number | Height  | Width | Quick Ship |
| 30828-055      | 76mm    | 437mm | No         |
| 30828-058      | 120.5mm | 437mm | No         |
| 30828-061      | 165mm   | 437mm | No         |
| 30828-067      | 253.8mm | 437mm | No         |

## ADDITIONAL PRODUCT DETAILS

The assembly kit for the front panel is included with the 19" chassis.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**